




Datasheet

New 3.5mm Plug with Flange 8A 3 Way

RS Stock 874-5146



Dimensions: (mm)

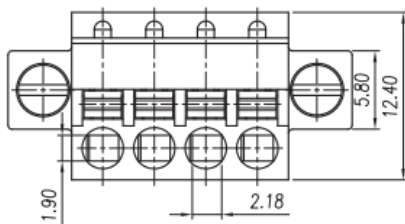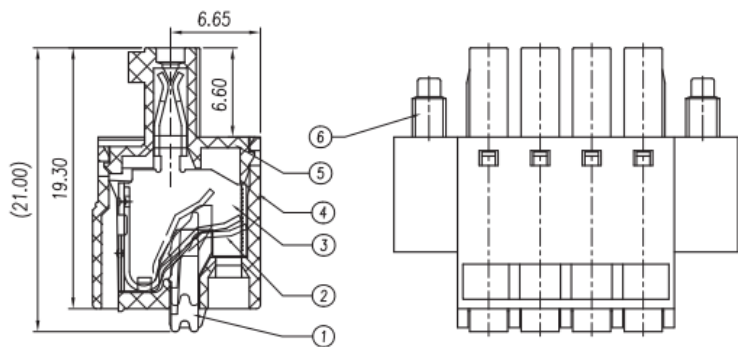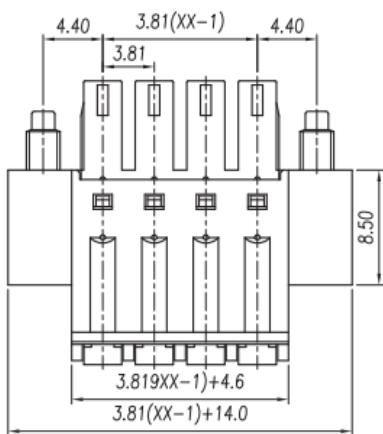

**ENGLISH**

Specifications

Mechanical

Steip Length	7-8mm
Temp.Range	-40°C~+105°C
Torque	0.4Nm(3.6Lb.in)

Dimensions

Pitch	3.81mm
Poles	2~24p

Material

Housing	PA66, UL94V-0
Screws	M2.5 Steel, Zn plated
Clamp	Phosphor bronze, Ni plated
Wire guard	Stainless steel

Standard	UL	IEC
Rated voltage	300V	250V
Rated current	8A	13.5A
Contact resistance	20mΩ	
Insulation resistance	500MΩ/DC500V	
Wire range	28~16AWG	1mm ²
Wrth standing voltage	AC 2000V/1 Min	