

MASTER LEDtube Value

LEDcontrol 6-20 GMT+1 sa su off 20x10

The Philips MASTER LEDtube integrates a LED light source into a traditional fluorescent form factor. Its unique design creates a perfectly uniform visual appearance which cannot be distinguished from traditional fluorescent. For those that are looking for value for money within limited budget and re-lamping efforts for better light effect and lifetime.

Product data

• General Characteristics

System Description	Single
Cap-Base Information	2P
Color of the Housing	Transparent

• Electrical Characteristics

Lamp Wattage	19-24 W
Voltage	220-240 V
Capacitor	No

• Luminaire Design Requirements

Ambient Temperature	-30 (min), 45 (max) C
---------------------	-----------------------

• Product Dimensions

Overall Length C	40.3 (max) mm
Overall Width E	21.5 (max) mm


• Product Data

Order code	926000130307
Full product code	926000130307
Full product name	LEDcontrol 6-20 GMT+1 sa su off 20x10
Order product name	LEDcontrol 6-20 GMT+1 sa su off 20x10
Pieces per pack	1
Packing configuration	20X10CT
Packs per outerbox	200
Bar code on pack - EAN1	8718291692607
Bar code on intermediate packing - EAN2	8718291692614
Bar code on outerbox - EAN3	8718291752646
Logistic code(s) - 12NC	926000130307
Net weight per piece	10.954 gr



PHILIPS

Dimensional drawing

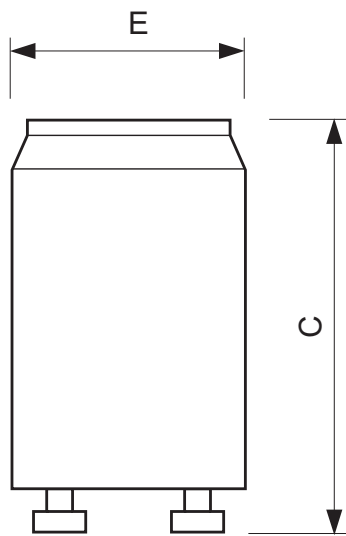

LEDcontrol 6-20 GMT+1 sa su off 20x10



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 11
data subject to change