

# 64 02 115


## Electronics End Cutting Nipper



- Precision pliers for ultra fine cutting work, e. g. in electronics and fine mechanics
- Sturdy, zero backlash box joint
- Low-friction double spring for gentle and even opening
- The polish or mirror polish (only finish 2) together with a fine film of oil offer effective rust protection - no circuit faults caused by peeling chrome from plated tools
- Cutting edges additionally induction hardened, cutting edge hardness at least 56 HRC
- High-grade special tool steel, forged, multi stage oil-hardened
  - Style:End Cutter, with bevel



|  |                            |
|--|----------------------------|
| <b>Article No.</b>   | 64 02 115                  |
| <b>EAN</b>   | 4003773082231              |
| <b>Head</b>  | mirror polished            |
| <b>Handles</b>   | with multi-component grips |
| <b>Style</b>   | 0                          |
| <b>Cutting capacities medium hard wire (diameter) Ø mm</b> | 1,0                        |
| <b>Cutting capacities hard wire (diameter) Ø mm</b>        | 0,6                        |
| <b>Cutting capacities soft wire (diameter) Ø mm</b>        | 2,0                        |
| <b>B mm</b>  | 6,0                        |
| <b>D mm</b>  | 7,5                        |
| <b>C mm</b>  | 16,0                       |
| <b>A mm</b>  | 11,0                       |
| <b>Length mm</b>   | 115                        |
| <b>Net weight g</b>  | 94                         |

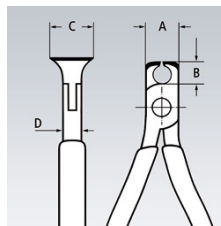

technical change and errors excepted

