


# 95 36 280

## Cable Cutter ratchet action

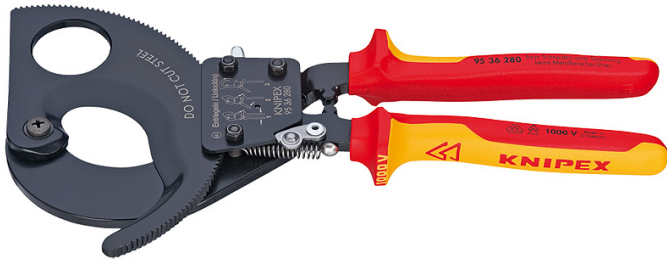

PATENTED



- for cutting copper and aluminium single conductors as well as multiple stranded cables
- not suitable for steel wire and wire ropes
- precision ground, hardened blades
- clean and smooth cut without crushing and deformation
- one-hand operation using ratchet principle
- little handforce required due to very high transmission ratio
- two-stage ratchet drive for easy cutting
- simple handling as a result of low weight and compact design - can be used even in confined areas
- guard prevents operators' fingers being pinched
- High-grade special tool steel, forged, oil-hardened
- suitable for aluminium sector cable up to 4 x 150 mm<sup>2</sup>

<b>Article No.</b>	95 36 280
<b>EAN</b>	4003773026891
<b>Tool</b>	black lacquered
<b>Handles</b>	insulated with multi-component grips, VDE-tested
<b>Insulation standard</b>	IEC 60900 DIN EN 60900
<b>Cutting capacity copper cable, multiple-stranded (diameter) Ø mm</b>	52
<b>Cutting capacity copper cable, multiple-stranded mm<sup>2</sup></b>	380
<b>MCM</b>	750
<b>Length mm</b>	280
<b>Net weight g</b>	835



Ratchet principle and two-stage ratchet drive for easier cutting

technical change and errors excepted



### Spare Parts

<b>Article No.</b>	<b>EAN</b>	
95 39 280	4003773025283	Movable spare blade for 95 31 280 / 95 36 280 ratchet action