


M 120/35.F


Spacing 35 mm (1.38")

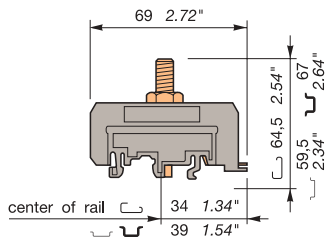

1 stud M8

M 300/42.F


Spacing 42 mm (1.65")

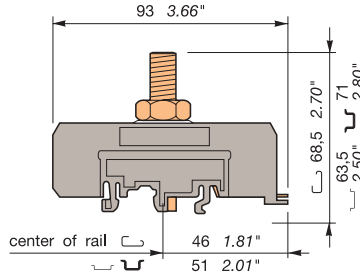

1 stud M10

M 35/26.FF

Spacing 26 mm (1.02")

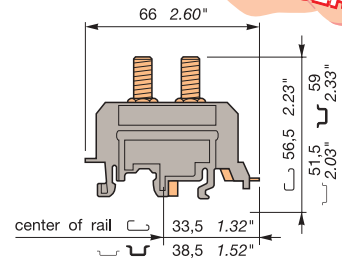

2 studs M6 linked by
1 removable bar 15 x 4 mm

END OF SERIES



Color	Type	Part number
Grey	M 120/35.F	0115 147.16



Color	Type	Part number
Grey	M 300/42.F	0115 150.25



Color	Type	Part numbers
Grey	M 35/26.FF	0115 140.23
Beige V0	M 35/26.FF.V0	0195 140.24

Characteristics

Wire size	DIN	NFC	UL	CSA	
	Lug	2,5-70 mm ²	6-95 mm ²	2-250 MCM	000 AWG max.
Bar	25 x 5 mm		1" x .20"		
Wire-clamp					
Voltage	IEC	IEC			
	V~ Without partition	1000	1000	600	600
	V~ With partition	1000	1000	600	600
Pulse	8 kV	8 kV			
Pollution degree	3	3			
Current	DIN	NFC			
	Rated	150 A	192 A	255 A	270 A

Characteristics

Wire size	DIN	NFC	UL	CSA	
	Lug	6-150 mm ²	50-150 mm ²	0-500 MCM	500 MCM
Bar	32 x 8 mm		1.26" x .32"		
Wire-clamp					
Voltage	IEC	IEC			
	V~ Without partition	1000	1000	600	600
	V~ With partition	1000	1000	600	600
Pulse	8 kV	8 kV			
Pollution degree	3	3			
Current	DIN	NFC			
	Rated	269 A	269 A	230 A	550 A

Characteristics

Wire size	DIN	NFC	UL	CSA	
	Lug	2,5-50 mm ²	4-35 mm ²	10-2 AWG	4 AWG max.
Bar	16 x 4 mm		.63" x .16"		
Wire-clamp					
Voltage	IEC	IEC			
	V~ Without partition	1000	1000	600	600
	V~ With partition	1000	1000	600	600
Pulse	8 kV	8 kV			
Pollution degree	3	3			
Current	DIN	NFC			
	Rated	125 A	101 A	115 A	125 A

Wire-size				
Rated	50 mm ²	70 mm ²	250 MCM	000 AWG max.
Lug	Central bolt	Wire-clamp	Wire stripping length	
H 13 mm				
6 Nm 52 lb.in				

Wire-size				
Rated	120 mm ²	120 mm ²	500 MCM	500 MCM
Lug	Central bolt	Wire-clamp	Wire stripping length	
H 16 mm				
10 Nm 87 lb.in				

Wire-size				
Rated	35 mm ²	25 mm ²	2 AWG	4 AWG
Lug	Central bolt	Wire-clamp	Wire stripping length	
H 10 mm				
4,5 Nm 39 lb.in				

Type	Part numbers		
BAEH	th. 12 mm	0116 934.04	
BADH	th. 12 mm	0116 900.27	
BAMH	th. 9,1 mm	0114 836.00	
ECP35		0113 691.16	
CPP351	1 block	0168 206.17	
CPP352	2 blocks	0168 205.16	
CPP353	3 blocks	0163 418.26	
CPU35		0116 514.07	

Type	Part numbers		
BAEH	th. 12 mm	0116 934.04	
BADH	th. 12 mm	0116 900.27	
BAMH	th. 9,1 mm	0114 836.00	
ECP42		0113 692.17	
CPP421	1 block	0168 208.21	
CPP422	2 blocks	0168 207.10	
CPP423	3 blocks	0163 424.14	
CPU42		0116 515.00	

Type	Part numbers		
BAEH	th. 12 mm	0116 934.04	
BADH	th. 12 mm	0116 900.27	
BAMH	th. 9,1 mm	0114 836.00	
ECP26		0113 689.24	
CPP261	1 block	0168 202.13	
CPP262	2 blocks	0168 201.12	
CPP263	3 blocks	0163 403.20	
CPU26		0114 882.07	

⑮ for ECP ⑥ for CPU

⑮ for ECP ⑥ for CPU

⑮ for ECP ⑥ for CPU