



Datasheet

Stock No: 748-2364

ENGLISH

RS Pro Blue/Grey Equipment Wire, 0.22 mm² CSA, 1000 V 24 AWG, 100m




BS 4808

Cable Construction

Conductor	Tinned Copper
square(mm ²)	0.22
Construction	T0.20±0.008×7
Standard Dia.(mm)	0.60
Insulation	PVC
Thickness	0.3
Insulation Dia.(±0.1mm)	1.20

Design

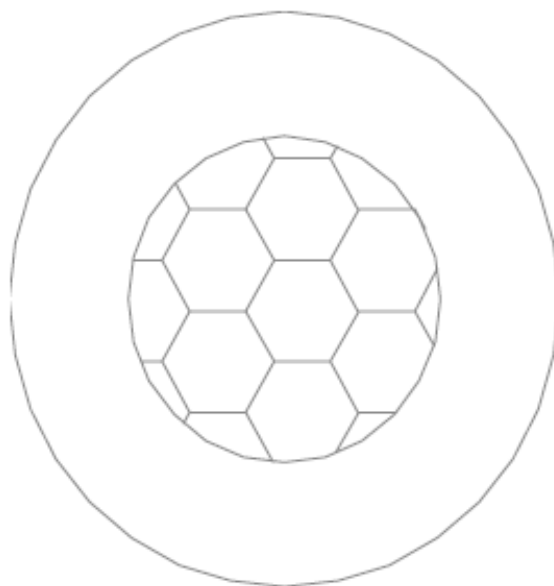

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<86.2
Min.Insulation DC Resistance at 20 °C ($M\Omega$ *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1000