


PPA43755

Dimensions 2, 3, 4, 6 U

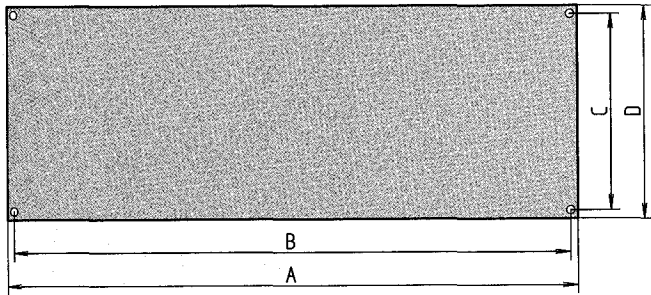


PPA43756

2-6 U

HP	A	B	U	C	D
28	167.6	158.9	2	74	84
42	238.7	230	3	118.5	128.5
63	345.4	336.7	4	162.9	172.9
84	452	443.3	6	258.8	261.8

Dimensions 1 U

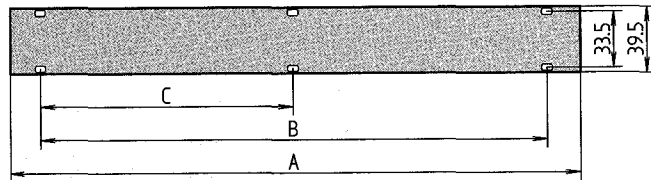

1 U

HP	A	B	C
28	141.9	127	-
42	213	198.1	101.6
63	319.7	304.8	157.5
84	426.4	411.5	208.3

PPA44169

**Ordering full-width front panel
2 U, 3 U, 4 U, 6 U, unshielded**

Delivery comprises

Item	Qty	Description	Material	Finish	Notes
1	1	Full-width front panel	Al 2 mm (84 HP ≈ 2.5 mm)	anodized, cut edges clean	
	1 kit	Assembly parts			

Delivery: in kit form



Case width HP	Order No. for 1 kit			
	2 U	3 U	4 U	6 U
28	-	20850-134	-	-
42	20850-128	20850-135	20850-142	-
63	20850-129	20850-136	20850-143	-
84	20850-130	20850-137	20850-144	20850-158

Ordering partial-width front panel 1 U, unshielded

Qty	Description	Material/Finish	Case width HP	Order No. for 1 piece
1	Front panel	Al 2.5 mm anodized, cut edges clean	28	-
			42	30850-479
			63	30850-483
			84	30850-487

Note

Please order assembly parts separately page 37.52