


THOROPROOF

Anti-corrosive polycarbonate luminaires for T8 and T5 lamps

Classified IP65  

- High-impact and corrosion-resistant light grey, injection moulded polycarbonate body
- Clear prismatic polycarbonate cover
- Body and cover flame-retardant
- Smooth easy-clean lines
- Snug-fit polycarbonate cover clips
- Fast installation via external stainless-steel brackets preserves IP rating
- Emergency and AutoTest versions available
- Optional narrow distribution reflector for rack lighting applications
- Complies with M.O.D. JSP482 Chapter 8 Document for 'Category C' areas

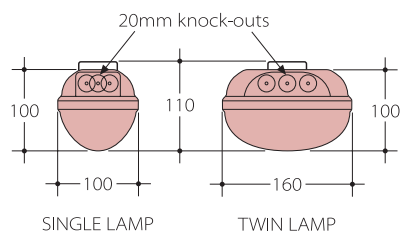

Range

NOMINAL SIZE (mm)	LAMP	CAT. No.	LENGTH (mm)	FIXINGS	APPROX. kg	STANDARD CIRCUIT	EMERGENCY CIRCUIT	AUTOTEST CIRCUIT
T8 LAMP VERSIONS								
1200	1 x 36W T8	TP 10411	1270	920mm centres	3.0	E-J-S	E-J	-
	2 x 36W T8	TP 10412			4.0	E-J-S	J	-
1500	1 x 58W T8	TP 10413	1570	1150mm centres	4.2	E-J-S	E-J	-
	2 x 58W T8	TP 10414			5.5	E-J-S	J	-
T5 LAMP VERSIONS								
1200	1 x 28W T5	TP 12075	1270	920mm centres	3.0	J	J	J
	2 x 28W T5	TP 13400			4.0	J	J	J
1500	1 x 35W T5	TP 11795	1570	1150mm centres	4.2	J	J	J
	2 x 35W T5	TP 11796			5.5	J	J	J
1500	1 x 49W T5	TP 11797	1570	1150mm centres	4.2	J	J	J
	2 x 49W T5	TP 11798			5.5	J	-	-

CIRCUIT - add suffix required: **E** - electronic start **J** - high frequency **S** - switch start e.g. **TP 10411E** etc.

EMERGENCY VERSION - prefix catalogue number with **ETP**: **AUTOTEST VERSION** - prefix catalogue number with **TTP**:

Emergency and AutoTest versions add 0.7kg to weights listed.

LAMPS MUST BE ORDERED SEPARATELY, SEE PAGES 92 AND 93 FOR DETAILS



DIRECT
Pair of stainless steel brackets supplied. Provides clearance for thermal expansion and fixing.




PENDANT
Pair of steel spring loops supplied.

THOROPROOF

Photometric Guide


SINGLE LAMP

D.L.O.R. 62% U.L.O.R 11% SHR max 2.34

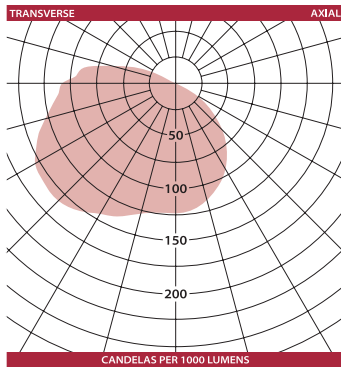

SINGLE LAMP with optional narrow distribution reflector

D.L.O.R. 64% U.L.O.R 4% SHR max 1.58

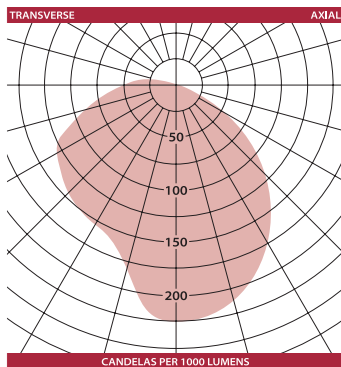

Spares and Accessories

DESCRIPTION	CAT. No.
Narrow distribution reflector (<i>Single 58WT8</i>)	TP 10415
Narrow distribution reflector (<i>Twin 58WT8</i>)	TP 10416
Narrow distribution reflector (<i>Single 35/49WT5</i>)	TP 11836
Narrow distribution reflector (<i>Twin 35/49WT5</i>)	TP 11835
IP65 20mm weatherproof compression gland kit with sealing washers	IK 6389
Stainless steel adjustable bracket (<i>Short</i>) - two per pack	IK 10419
Stainless steel adjustable bracket (<i>148mm long</i>) - two per pack	IK 10420
Stainless steel suspension hook - two per pack	IK 10421
Stainless steel cover clip - eight required per 1200mm body - ten required per 1500mm body	TP 10541


Through wiring kits are available - details upon request




TP 10415




TP 10416

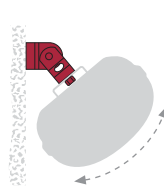

IK 10419

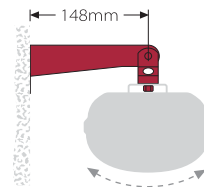

IK 10420

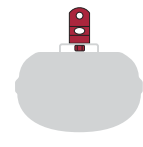

IK 10421

