





cylinder

Zylinderform

cylindrique

cilindro

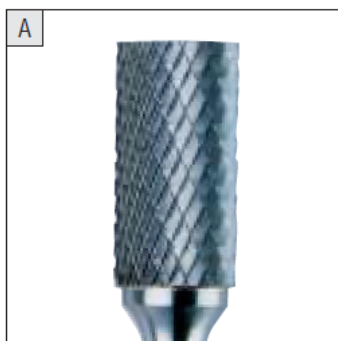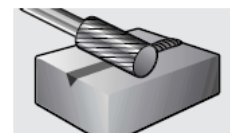

	d1 mm	1.5	2.4	2.4	3	3	4	4	4	6	6	6	8
	l1 mm	6	13	13	13	13	13	13	16	13	19	19	19
	d2 mm	3	2.4	2.4	3	3	4	4	6	3	6	6	6
	l2 mm	38	38	63	38	63	50	63	50	45	50	75	65
	s	T1050	T1100	-	T1200	-	T1300	-	T1300-6	T1240	T1400	T1400L	-
	d	T1050D	T1100D	T1100DL	T1200D	T1200DL	T1300D	T1300DL	T1300D-6	T1240D	T1400D	T1400DL	T1400D-1
	d-max	-	-	-	-	-	-	-	-	-	-	-	-
	c	-	-	-	-	-	-	-	-	-	T1400C	-	-
	k	-	-	-	T1200K	-	-	-	-	-	T1400K	-	T1500K
	alu	-	-	-	-	-	-	-	-	-	TTA240	-	-
	I.S.O. Ref.	-	-	-	A031303	A031303	A041304	A041304	A041304	A061303	A061906	A061906	A062506
	SCTI Nr.	SA-41M	SA-63M	-	SA-43M	-	-	-	SA-13M	SA-51M	SA-1M	SA-1ML3	SA-1ML