


Datasheet


# RS Pro 2 Core Multicore Speaker Cable, PVC Insulation 60V

Stock No: 714-0313

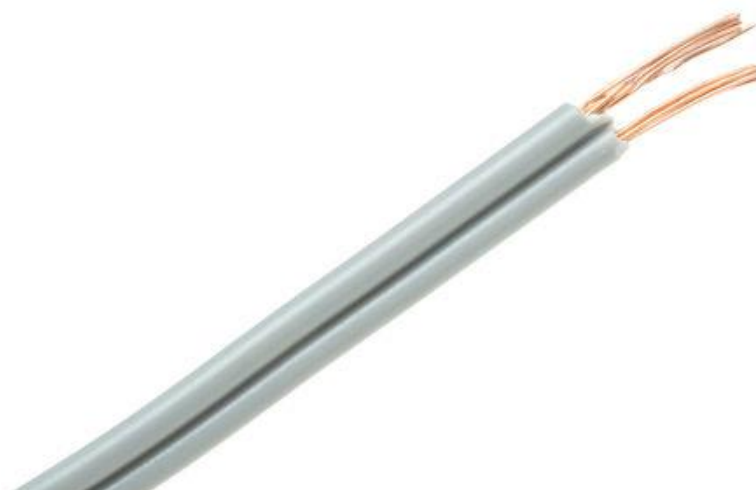

## Cable Construction

<b>Conductor</b>	<b>Tinned Copper</b>
Construction	T0.2±0.008×13
Standard Dia.(mm)	0.83
<b>Insulation</b>	<b>PVC</b>
Thickness	0.57
Insulation Dia.(±0.1mm)	2.0×2
Insulation Color	Grey
Marking	One Black Stripe on one leg of Twin
<b>Print Marking</b>	
2 Core 7/0.25mm 60 V PVC [MM] [WkYr]	
<b>Packaging</b>	
100M/Cardboard Reel	

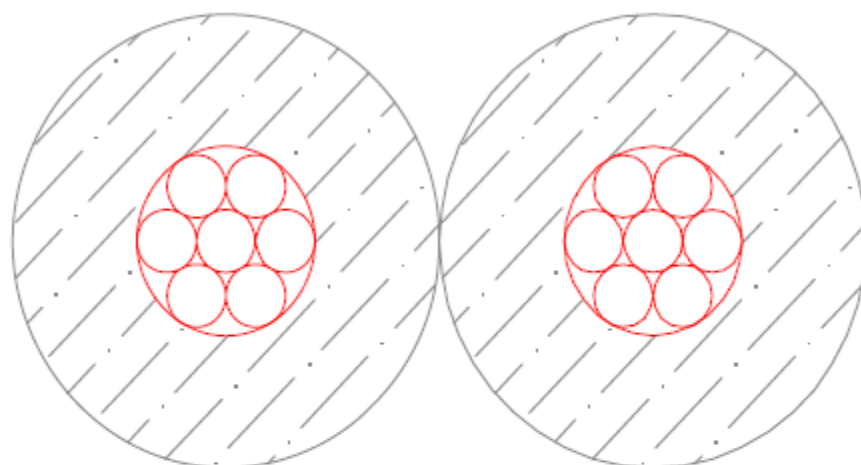

### Electrical Characteristics

Max.Conductor DC Resistance at 20°C ( $\Omega$ /Km)	<55.2
Min.Insulation DC Resistance at 20 °C (M $\Omega$ *Km)	200
Rated Temperature(°C)	80
Rated Voltage (V)	60