


PHE L090HUB

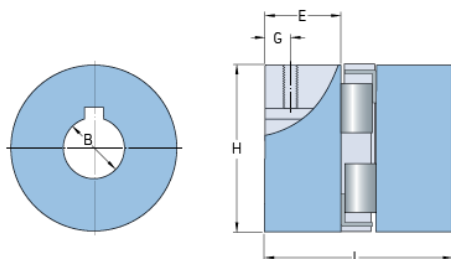

Size	90
Position threaded hole G (mm)	8.7
Position threaded hole G (in)	0.34
Outer diameter H (mm)	54
Outer diameter H (in)	2.13
Maximum bore	24
Maximum bore (in)	-
Set screw	M6
Length E (mm)	21
Length E (in)	0.83
Bore	9
Bore (in)	0.35