


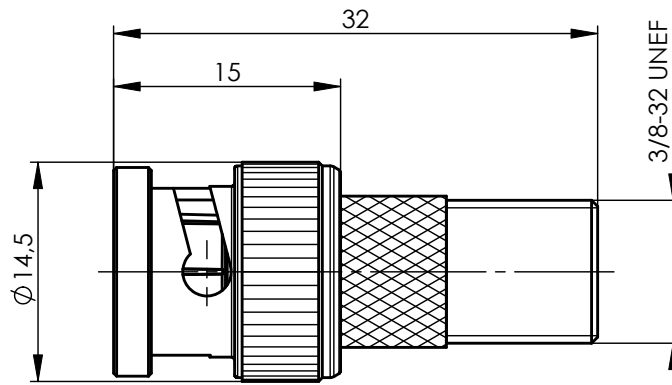

Mechanical characteristics
interface dimensions acc. to

Mechanische Eigenschaften
Steckgesicht nach

BNC - IEC 61169-8
F - IEC 61169-24

Components
centre contact
outer contact
other metal parts
insulator
gasket

Bauteile
Innenkontakt
Aussenkontakt
sonstige Metallteile
Isolierung
Dichtung

Materials / Material
brass/Messing
brass/Messing
brass/Messing
PP / POM
silicone/Silikon

Finish / Oberfläche
gold plated/vergoldet
nickel plated/vernickelt
nickel plated/vernickelt

Electrical characteristics
impedance
return loss

Elektrische Eigenschaften
Wellenwiderstand
Rückflussdämpfung

50 Ω
typ.: 1 GHz - 9 dB; 2 GHz - 9 dB;
3 GHz - 6 dB

Environmental
RoHS compliant

Umgebung
RoHS konform

2002/95/EC

				2010	Datum/ date	Name/ name	Gewicht/ weight [g]	Oberfläche/ surface [mm²]	Werkstoff/ material
				gez./ drawn	16.08.	MA			
				gepr./ appr.	16.08.10	BJ			Oberfläche/ finish
				Norm/ stand.					
				Maßstab/ scale 2:1	Benennung/ title Adaptor BNC-F (m-f) Adapter BNC-F (m-f)				
					untol. Maße/ dim. without tolerances according to	Unterl./doc. type K	Zeichnungsnr./ drawing no. J01008A0023		
Änd./ rev. Index	Änderungsmittelung/ revision code	Datum/ date	Name/ name	Ersatz für/ replaces	Original : DIN A4 Blatt/ sheet 1 von/ of 1				