



Muffin XL AC - MX77A2 - 028989

(Family)

(Model)


(Part Number)

Electrical Specifications

Rated Voltage:	230 VAC
AC Frequency:	60 Hz
Power Supply:	15.0 Watts
Line Current:	0.08 Amps
Locked Rotor Current	0.12 Amps
Nominal Speed:	2940 RPM

Mechanical Specifications

Dimensions:	4.72in x 1.50in
Weight	21.0 oz
Max Airflow @ 0 in H ₂ O	105.0 CFM
Max Pressure @ 0 CFM	0.223 in H ₂ O
Noise	47.6 dBA

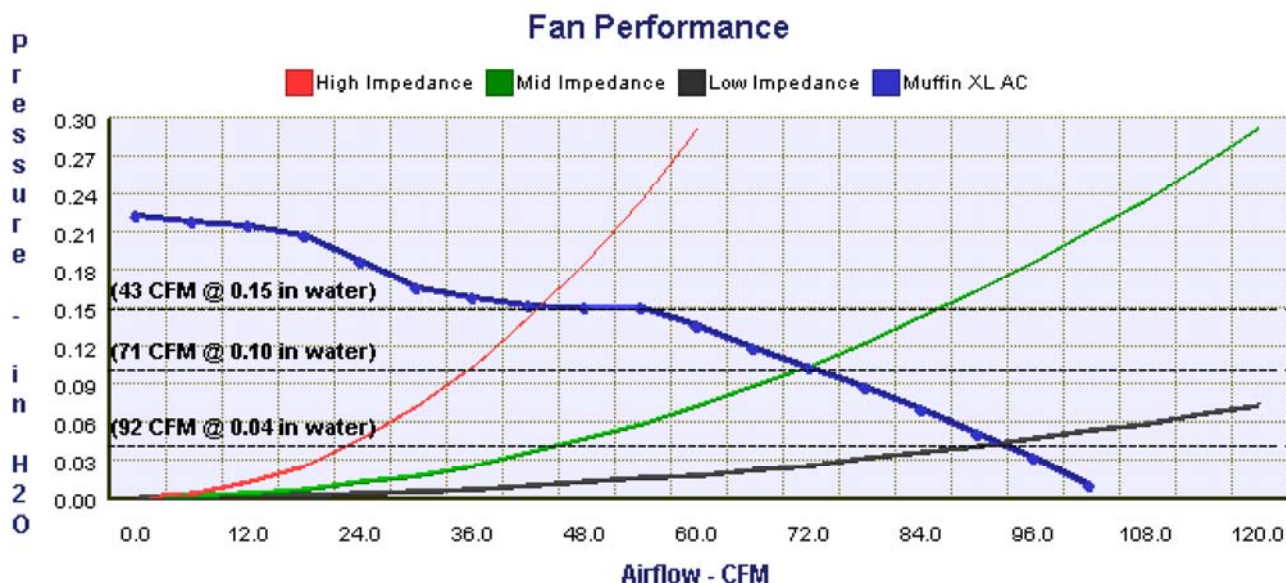

Comair Rotron, Inc.
Phone: 619.651.2000
sales@comairrotron.com


Comair Rotron Europe, Ltd.
Phone: +44.1527.520525
saleseurope@comairrotron.com

Comair Rotron Fan Company Ltd.
Phone: +86.21.52260581
salesasia@comairrotron.com

Print Date: Wednesday, November 10, 2010 at 09:56:07 - AC Fan Datasheet - Web Version 1.0 Rev. A



Mechanical Drawing

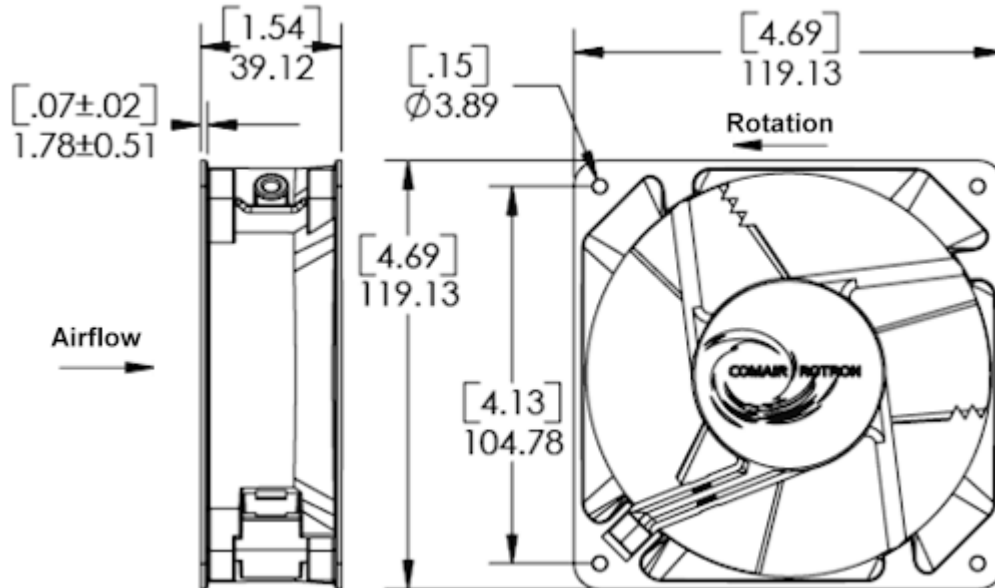


Options


Part Number	Model Number	Bearing Type	Fan Rotation	Termination	In-Stock (Click 'Yes' for current stock)
○ 028793	MX77B3	Ball	Reverse	0.120 Terminals	No
○ 028781	MX77A1	Sleeve	Normal	0.120 Terminals	No
● 028989	MX77A2	Sleeve	Normal	Leads	No
○ 028792	MX77A3	Sleeve	Reverse	0.120 Terminals	No

Accessories [\(Click on part number for detailed drawing.\)](#)

☐ **428056**
Plug and Cord

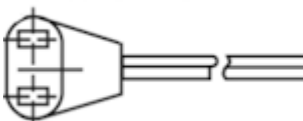


☐ **550440**
Plug and Cord

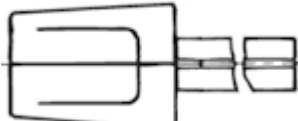

☐ **550113**
Mounting Clip



☐ **551590**
Filter Assembly
Mounting Bracket
Filter Frame
Filter Element
Fan
Venturi Edge

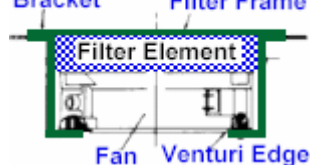


☐ **554148**
Filter Guard Assembly




☐ **552934**
Finger Guard

☐ **476042**
Finger Guard

☐ **550481**
Finger Guard

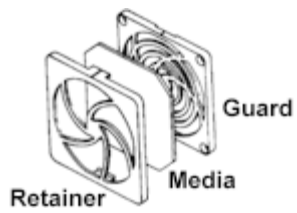

☐ **551147**
Finger Guard

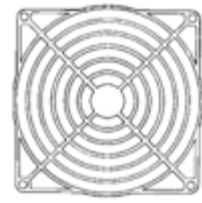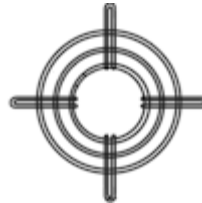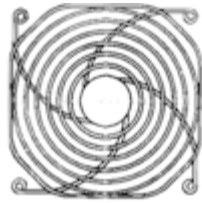

Comair Rotron, Inc.
Phone: 619.651.2000
sales@comairrotron.com

Comair Rotron Europe, Ltd.
Phone: +44.1527.520525
saleseurope@comairrotron.com

Comair Rotron Fan Company Ltd.
Phone: +86.21.52260581
salesasia@comairrotron.com

Print Date: Wednesday, November 10, 2010 at 09:56:07 - AC Fan Datasheet - Web Version 1.0 Rev. A