

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



16-channel analog input module with screw connection, redundant voltage supply, and additional jumpers for each channel. Suitable for Yokogawa SAI 143 card.

### Product description


These modules have been specifically developed to connect analog I/O cards to the field level using pre-assembled system cables. The modules offer the following features:

- Transmission of up to 16 channels
- Two parallel system connections for redundant applications
- Fuse and LED per channel
- 2 or 3-wire connection for each channel depending on the jumper position
- Screw connection

The following input cards can be connected:  
SAI 143



### Key commercial data

Packing unit	1
GTIN	 4 046356 906937
Custom tariff number	85369010

### Technical data

#### Dimensions

Width	182 mm
Height	128 mm
Depth	94 mm

#### Ambient conditions

Ambient temperature (operation)	-20 °C ... 55 °C
---------------------------------	------------------

#### General

Max. permissible operating voltage	24 V DC
Max. perm. current (per branch)	1 A
Max. permissible current (separate power supply)	10 A
Mounting position	any

# Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

## Technical data

### General

Designation	Air and creepage distances
Standards/regulations	DIN EN 50178
Rated insulation voltage	50 V
Rated surge voltage	0.8 kV (basic insulation)
Pollution degree	2
Surge voltage category	III

### Connection data for connection 1

Connection name	Field level
Number of connections	1
Connection method	Screw connection
Number of positions	66
Conductor cross section solid min.	0.2 mm <sup>2</sup>
Conductor cross section solid max.	4 mm <sup>2</sup>
Conductor cross section stranded min.	0.2 mm <sup>2</sup>
Conductor cross section stranded max.	2.5 mm <sup>2</sup>
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	12

### Connection data for connection 2

Connection name	Controller level
Number of connections	2
Connection method	Yokogawa KS-compatible
Number of positions	40

### Supported controller

Controller	YOKOGAWA ProSafe-RS
- suitable I/O card	SAI143

## Classifications

### eCl@ss

eCl@ss 4.1	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27371601

### ETIM

ETIM 4.0	EC001437
ETIM 5.0	EC001437

## Accessories

### Accessories

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

#### System cable

Cable - FLK 40-PA/EZ-DR/KS/ 100/YUC - 2322786



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 1.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 200/YUC - 2314341



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 2.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 300/YUC - 2314354



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 3.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 400/YUC - 2314367



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 4.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 500/YUC - 2321570



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 5.0 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/ 600/YUC - 2314943



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 6.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 700/YUC - 2321583



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 7.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 800/YUC - 2314956



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 8.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/ 900/YUC - 2321415



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 9.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1000/YUC - 2314370



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 10.0 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/1100/YUC - 2321428



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 11.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1200/YUC - 2321431



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 12.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1300/YUC - 2321444



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 13.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1400/YUC - 2321457



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 14.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1500/YUC - 2314383



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 15.0 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/1600/YUC - 2321596



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 16.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1700/YUC - 2321606



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 17.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1800/YUC - 2321619



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 18.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/1900/YUC - 2321622



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 19.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/2000/YUC - 2314532



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 20.0 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/KS/2500/YUC - 2314545



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 25.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/3000/YUC - 2314558



Round cable set, with two 40-pos. molded socket strips (1:1 connection). Length of cable: 30.0 m

---

Cable - FLK 40-PA/EZ-DR/KS/3500/YUC - 2901017



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 35.0 m.

---

Cable - FLK 40-PA/EZ-DR/KS/4000/YUC - 2901052



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 40.0 m.

---

Cable - FLK 40-PA/EZ-DR/KS/4500/YUC - 2902912



Assembled round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 45.0 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/ 100/YUC - 2904747



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 1 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 200/YUC - 2904748



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 2 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 300/YUC - 2904749



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 3 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 400/YUC - 2904750



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 4 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 500/YUC - 2904645



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 5 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/ 600/YUC - 2904751



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 60 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 700/YUC - 2904752



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 7 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 800/YUC - 2904753



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 8 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/ 900/YUC - 2904754



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 9 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/1000/YUC - 2904646



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 10 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/1500/YUC - 2904647



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 15 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/2000/YUC - 2904488



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 20 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/2500/YUC - 2904648



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 25 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/3000/YUC - 2904649



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 30 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/3500/YUC - 2904650



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 35 m

---

## Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

### Accessories

Cable - FLK 40-PA/EZ-DR/HF/KS/4000/YUC - 2904651



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 40 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/4500/YUC - 2904652



Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 45 m

---

Cable - FLK 40-PA/EZ-DR/HF/KS/5000/YUC - 2904653




Assembled halogen-free round cable with two molded 40-pos. socket strips (1:1 connection). Cable length: 50 m

---

### Drawings

# Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

Dimensioned drawing

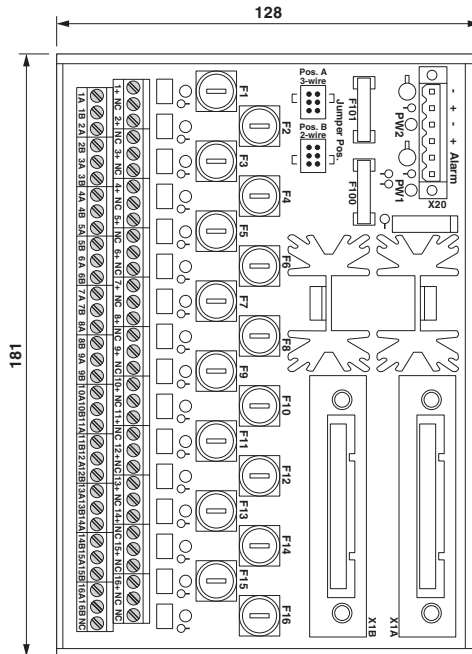

# Input module - UM-2KS40/16AI-J/SI/RS/SO225 - 2905003

Circuit diagram

