


Deep groove ball bearings, single row, seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
50	110	27	65	38	1,6	-	4300	1,05	6310-2RS1 *

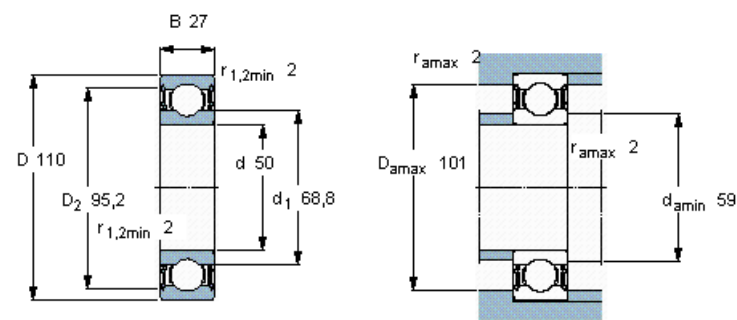

Calculation factors

k_f 0,03
 f_0 13