

#4127 - Single round screen cable, 25m reel



Part NO: #4127

Product Code: RGW-1568

Product Description

Application:

For communication and signal control systems.

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

1

Cable Construction

Conductor **Bare Copper**

Construction 0.2±0.005x16

Stranded Dia.(±0.015mm) 0.92

Insulation **PVC**

Thickness 0.45

Insulation Dia.(±0.1mm) 1.85

Insulation Color Red

Braid **Bare Copper**

Construction (mm) 0.10±0.003×16 x 6

coverage >=91%

Jacket **PVC**

Thickness(mm) >=0.65

Dia.(±0.15mm) 3.40

Jacket Color Grey (RAL7001)

Marking

Single round braided screen cable ww/yy +Meter marking

PACKAGING

25M/Reel

RoHS GUIDELINE


We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls (PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Revision History

A0-1

Design

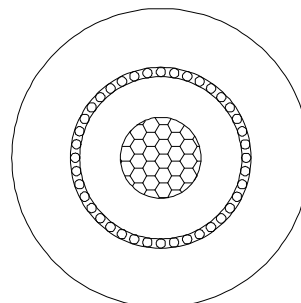

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km) 37

Min.Insulation DC Resistance at 20°C (MΩ *Km) >500

Rated Temperature(°C) -20 to +60

Rated Voltage(V) 30

Capacitance Core to Screen 360pF/m

Label on Reel

Product label

Single round screen cable

Grey

25M

RoHS(2002/95/EC) Compliant

WW/YY

Date: 2011-09-13

Page: 1 / 1