



Double hexagon Metric, 7800DM

Sockets Double Hexagon Metric

 

DIN 3124/ISO 2725.

1/2" 12.5 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.

Material: CHROME-EXTRA.

With Dynamic-Drive-Profile.

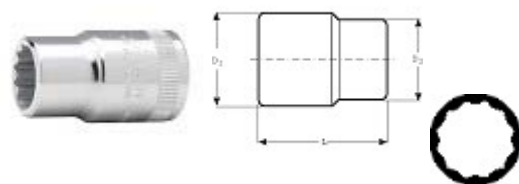

L
mm

D1
mm

D2
mm

7800DM-25	1097295	5	25	42	34.1	27.0 124
7800DM-26	1097318	5	26	43	35.4	28.0 136
7800DM-27	1097332	5	27	44	36.6	29.0 173
7800DM-28	1097356	5	28	45	37.9	27.6 173
7800DM-29	1097363	5	29	46	39.1	28.6 175
7800DM-30	1097370	5	30	47	40.4	29.5 189
7800DM-32	1097387	5	32	47	42.9	30.5 227
7800DM-36	1097400	1	36	57	50.0	42.0 315