


Terminal blocks spring clamp

ground terminal blocks electrically connected to the mounting rail

DIN 3

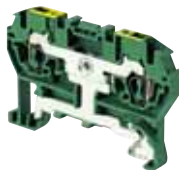

Other accessories of this terminal blocks:
See pages of same size standard blocks.

Characteristics		IEC	UL/CSA		
Wire size	Rigid Flexible	NFC DIN	22-8 AWG	22-8 AWG	
Rated current short-circuit		720 A/1s	720 A/1s		
Rated wire size nominal / gauge		6 mm ² / A5	8 AWG		
Other characteristics		Wire strip. length	Recomm. screwdriver	Protection	
		12,5 mm .49"	5,5 mm .22"	IP 20 NEMA 1	
Approvals					
Accessories		Type	P/N	Type	P/N
1	End section	FED8.2L V0 th. 2,5 mm	1SNA 291 161 R2500	FED8.3L V0 th. 2,5 mm	1SNA 291 711 R2400
2	Test plug	FED8.2L V0 th. 2,5 mm	1SNA 291 162 R2600	FED8.3L V0 th. 2,5 mm	1SNA 291 713 R2600
R	See section on markers	On top: RC610, RC810, RPC On sides: RC85AL		On top: RC610, RC810, RPC On sides: RC85AL	

D 6/8.P.2L

Spacing 8 mm - 0,05 .315"

2 springs.

Type	P/N
Green body / Yellow marking	
D 6/8.P.2L	1SNA 290 089 R0400

D 6/8.P.3L

Spacing 8 mm - 0,05 .315"

3 springs.

Type	P/N
Green body / Yellow marking	
D 6/8.P.3L	1SNA 290 422 R2600

D 10/10.P.2L

Spacing 10 mm - 0,05 .394"

Terminal block with 2 springs and 1 test + 1 interconnection on one side.

Type	P/N
Green body / Yellow marking	
D 10/10.P.2L	1SNA 290 299 R1300

Terminal blocks spring clamp

ground terminal blocks electrically connected to the mounting rail

DIN 3

Other accessories of this terminal blocks:
See pages of same size standard blocks.
* Max. current according to rail. Consult us.

Characteristics		IEC	UL/CSA		
Wire size	Rigid Flexible	NFC DIN	20-6 AWG	20-6 AWG	
Rated current short-circuit		1200 A / 1 s.	1200 A / 1 s.		
Rated wire size nominal / gauge		10 mm ² / B6	6 AWG		
Other characteristics		Wire strip. length	Recomm. screwdriver	Protection	
		12 mm .47"	5,5 mm .22"	IP 20 NEMA 1	
Approvals					
Accessories		Type	P/N	Type	P/N
1	End section	FED10.2L V0 th. 2,5 mm	1SNA 291 461 R2200	FED10.3L V0 th. 2,5 mm	1SNA 291 731 R2000
2	Test plug	FED10.2L V0 th. 2,5 mm	1SNA 291 462 R2300	FED10.3L V0 th. 2,5 mm	1SNA 291 733 R2200
R	See section on markers	On top: RC1010, RC810, RC610, RPC On sides: RC85AL, RC65		On top: RC1010, RC810, RC610, RC510, RPCV On sides: RC85, RC35	

D 10/10.1.P.2L

Spacing 10 mm - 0,05 .394"

Terminal block with 2 springs with 2 interconnections on one side.

Type	P/N
Green body / Yellow marking	
D 10/10.1.P.2L	1SNA 290 309 R2500

D 10/10.P.3L

Spacing 10 mm - 0,05 .394"

Type	P/N
Green body / Yellow marking	
D 10/10.P.3L	1SNA 290 427 R2300

D 16/12.P.2L

Spacing 12 mm - 0,05 .473"

Terminal block with 2 springs with 1 test + 1 interconnection on both sides.

Type	P/N
Green body / Yellow marking	
D 16/12.P.2L	1SNA 399 584 R2200