

Selectronic Shower Safe

Thermostatic Electric Showers

The Selectronic Shower Safe range combines unique microprocessor thermostatic controls with contemporary styling to give the ideal shower for all the family. Its simple to use push button controls with premium chrome accessories make it both 'safe' and 'stylish'.

Application Family showering.

Key Features One-touch operation | Tactile button coding with large, easy to press buttons | Heat exchanger designed to minimise the build up of scale | LED digital readout | Independent adjustment for both temperature and water flow rate.

Safety Features Fully thermostatic - adjusting power and water flow to achieve selected temperature | Microprocessor thermostatic control for safety and comfort | Preprogrammed start up temperature of 41°C | Phased shutdown - reducing scale and ensuring cool-start use | Audible feedback response commands | Auto shut off to protect against high temperatures.

Outer Casing White | High impact | Easy clean | Scratch resistant | Thermoplastic.


Accessories Premium chrome accessories kit: 6 mode shower rub clean handset | Riser rail with fully adjustable handset holder | Soap dish | Chrome shower hose.

Pressure Operating pressure - 0.7bar - 10bar.

Approvals BEAB Approved | CE.

Guarantee* 3 year product guarantee (UK).

Dimensions

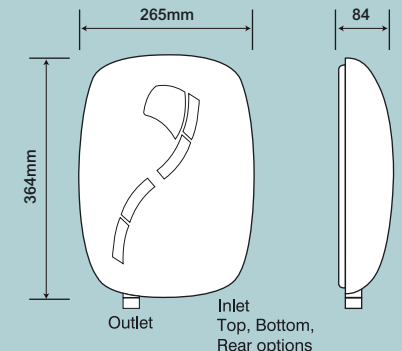

Technical Specification

Operating water pressure 0.7-10bar (10-145psi) | Cable entries: top, bottom and rear (up to 16mm²) | Pipe entries: top, bottom, and rear (on right hand side) | Water connection - 15mm plain shank tails push fit or standard compression fitting.

kW variant	kW loading at 230-240V	Recommended cable sizes	Recommended fuse ratings
8.5	7.8 - 8.5	6 - 10mm ²	40 amps
9.5	8.7 - 9.5	6 - 10mm ²	45 amps
10.8	9.9 - 10.8	10 - 16mm ²	45 amps

Product Range

Product Reference	Short Code	Cat. No
Selectronic Safe 8.5kW	SEL85T	53557020
Selectronic Safe 9.5kW	SEL95T	53558020
Selectronic Safe 10.8kW	SEL108T	53559020

*The final year of the guarantee is only available for products registered with Redring after purchase.

8.5 kW

9.5 kW

10.8 kW

3 yr GUARANTEE

BEAB Approved

CE

