

## ToLEDo Candle

*ToLEDo Candle Dim Frosted 250LM E14 SL*

**0026925**



### Range features

- Up to 88% energy saving compared to incandescent lamps
- Instant light
- 100% retrofit - Same dimensions as incandescent equivalent
- Suitable for replacement of up to 25W and 40W incandescent lamps
- Uniform light distribution
- Available in Homelight (2700K)
- Good colour rendering (CRI 80+)
- Average rated life 25,000 hrs



### PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026925
Average life (Rated) (h)	25000
Energy class	A+
Lamp shape	Candle
Lamp finish	Frosted
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Candle
EAN code	5410288269252
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Watt (Nominal) (W)	4.5
Equivalent watt (W)	25
Voltage (V)	220-240

## ToLEDo Candle

ToLEDo Candle Dim Frosted 250LM E14 SL

0026925

### DATA TABLE

#### General data

Ordering number	0026925
Dry applications use only	Yes
Technology	LED
Energy saving lamp	Yes
Energy class	A+
Average life (Rated) (h)	25000
Average life (Nominal) (h)	25000
Lamp finish	Frosted
Lamp shape	Candle
Dimmable	Yes
Cap/Base	E14
Type	ToLEDo Candle
EAN code	5410288269252
E-number FI	4740194
Long description	Up to 88% energy saving compared to incandescent lamps. Instant light. 100% retrofit - Same dimensions as incandescent equivalent. Suitable for replacement of up to 25W and 40W incandescent lamps. Uniform light distribution. Available in Homelight (2700K). Good colour rendering (CRI 80+). Average rated life 25,000 hrs
Product name	ToLEDo Candle Dim Frosted 250LM E14 SL
Lamp mercury content (mg)	0
Starting time (max) (s)	0.05
Warm-up time to 60% of full light (max) (s)	< 1s => 60%
Control gear required	No
Intended purpose	No
No. of switching cycles before premature failure (min)	50000
Special purpose lamp	No
Sales pack quantity	6
Optimal operating condition (°C)	25

#### Optical data

Light colour	Homelight
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	250
Lumen maintenance at end of nominal life (%)	70
Luminous flux (Nominal) (lm)	250

## ToLEDo Candle

*ToLEDo Candle Dim Frosted 250LM E14 SL*

**0026925**

### Electrical data

<b>kWh per 1000 hours burning time</b>	5
<b>Watt (Rated) (W)</b>	4.5
<b>Watt (Nominal) (W)</b>	4.5
<b>Equivalent watt (W)</b>	25
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	0.55

### Physical data

<b>Weight (kg)</b>	0.06
<b>Lamp Length (mm) - C/L</b>	112
<b>Max. Lamp Diameter (mm) - D</b>	38
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	12.60 x 4.80 x 4.80
<b>Inner package dimensions (L x W x H) (cm)</b>	15.50 x 10.50 x 14.10
<b>Inner package net weight (kg)</b>	0.38
<b>Outer package dimensions (L x W x H) (cm)</b>	55.00 x 32.60 x 16.10


## ToLEDo Candle

*ToLEDo Candle Dim Frosted 250LM E14 SL*

**0026925**

### TECHNICAL DRAWINGS

---

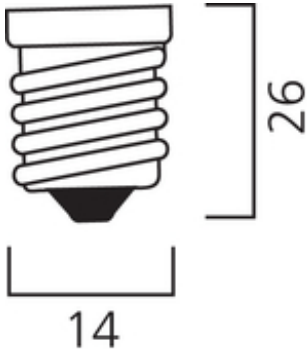

### ENERGY LABEL

---

□