

(2,54mm) .100"

TS, TD, HTS SERIES

TS-120-G-A-1

TD-108-G-AA

PRECISION MACHINED TERMINAL STRIPS

SPECIFICATIONS

For complete specifications see
www.samtec.com?TS or
www.samtec.com?TD

TS, TD

Insulator Material:

Black G.F. Polyester

Terminal Material:

Brass, except Style G is
Phosphor Bronze

Plating:

Au over 50µ" (1,27µm) Ni or
Sn over 100µ" (2,54µm) Cu
or 50µ" (1,27µm) Ni

Operating Temp Range:

-55°C to +125°C with Gold

-55°C to +105°C with Tin

Current Rating:

1A

RoHS Compliant:

Yes

Lead-Free Solderable:

Wave only



Mates with:
SS, SD, HSS, SL,
SDL, ESS, ESD

 
Note: Some lengths,
styles and options are
non-standard, non-returnable.

TYPE
STRIP


1

NO. PINS
PER ROWPLATING
OPTIONLEAD
STYLE


TS
= Single
Row Terminal
Strip



 HTS
= Single Row
High Temp
Terminal Strip



TD
= Double Row
Terminal Strip

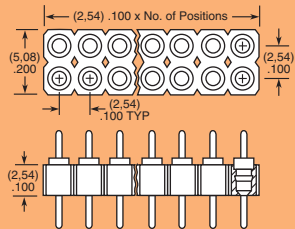

-G

= 20µ" (0,51µm) Gold
Except -J & -L are 10µ"
(0,25µm) Gold

-T

= Tin

01 thru 32
= TS Series

01 thru 36
= HTS & TD Series

SPECIFICATIONS

For complete specifications see
www.samtec.com?HTS

HTS

Same as TS except:

Insulator Material:


Black Liquid Crystal Polymer

Lead-Free Solderable:

Wave, or reflow with all Au




-AA

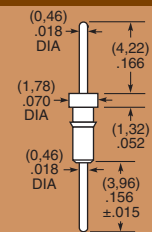

Component No. = T-1R5-


-A, -A-1, -A-2

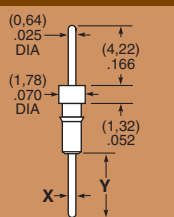

-A Component No. = T-1R0-
-A-X Component No. = T-1R7

LEAD STYLE	X (DIA)	Y (±.015)
-A	(0,46) .018	(3,96) .156
-A-1	(0,64) .025	(5,33) .210
-A-2	(0,89) .035	(5,33) .210


-C, -C-1, -C-2

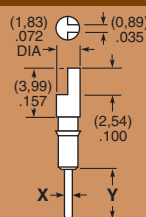

-C Component No. = T-1R2-
-C-X Component No. = T-1R9-


LEAD STYLE	X (DIA)	Y (±.015)
-C	(0,46) .018	(3,96) .156
-C-1	(0,64) .025	(5,33) .210
-C-2	(0,89) .035	(5,33) .210

-G-1

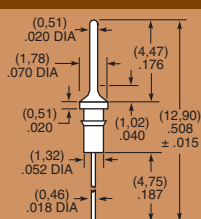


Component No. = T-1R5-

-J

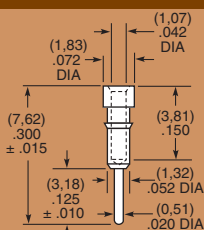

Component No. = S-1P1-

-L-1, -L-2, -L-3

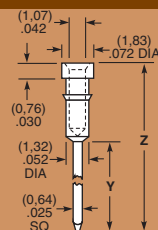

Component No. = S-1W1

LEAD STYLE	Y (DIA)	Z (±.015)
-L-1	(12,95) .510	(17,86) .703
-L-2	(9,14) .360	(14,05) .553
-L-3	(6,60) .260	(11,51) .453

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683