

**1-925366-0 -- 1 of 1 products**


**AMPMODU**

**Locking Clip, Mod. IV and Short Point Products**

General **INFO**  
Sales **INFO**  
Customer Drawings **SPECIFICATIONS**

**Ohne Verriegelung**

**Without Strain**

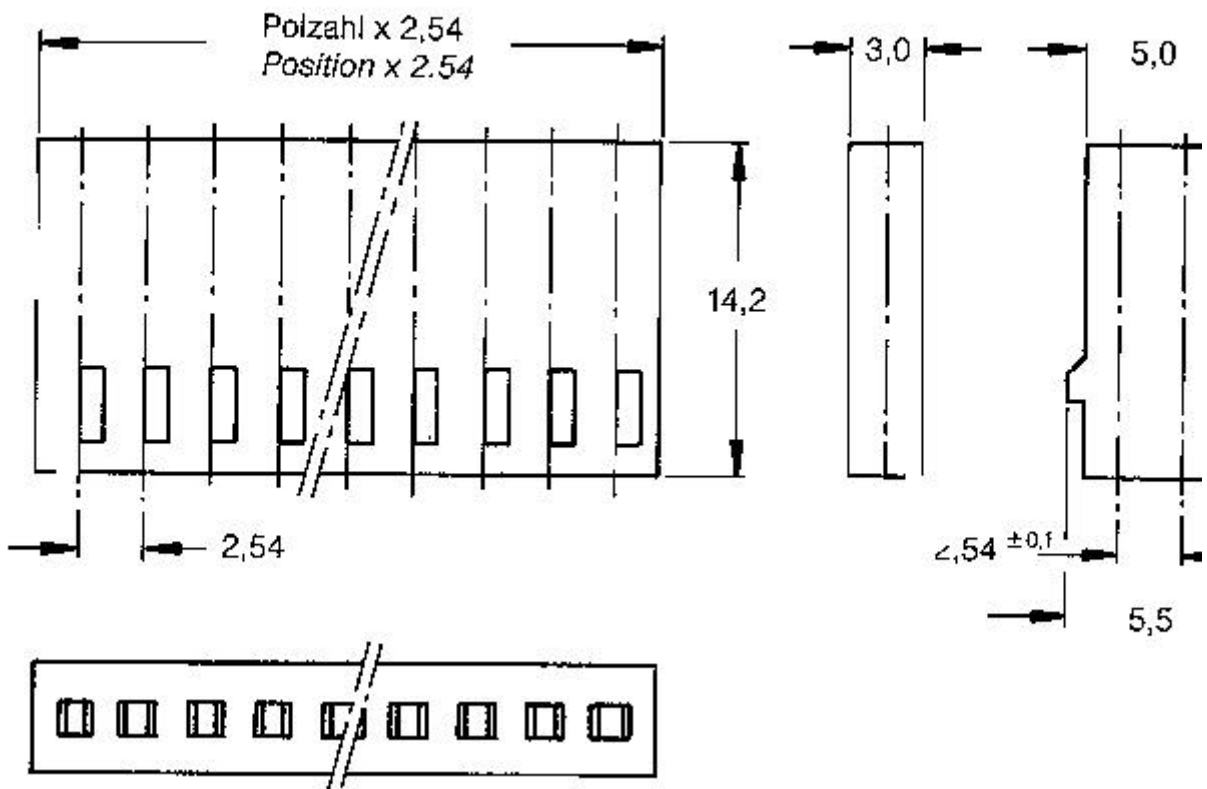

*Line art represents typical product only.*

<b><i>Searchable Features:</i></b>	
<b># of Positions</b>	10
<b># of Rows</b>	Single
<b>Centerline Spacing</b>	.100 [2.54] in. [mm]
<b>Housing Configuration</b>	Both Ends Closed
<b>Contact Type</b>	Mod IV, Mod V
<b>Mating Polarization</b>	No
<b>Mating Connector Lock</b>	Without
<b>Strain Relief</b>	Without
<b>Keyed</b>	No
<b><i>Other Properties:</i></b>	
<b>Housing Material</b>	Nylon
<b>Housing Flammability Rating</b>	UL 94-HB
<b>Housing Color</b>	Green

---

[ [Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#) ]  
[Top of Page](#)