

# Datasheet

## Metal Conical Stop Rubber +80°C -40°C Threaded Stud 70mm 25mm M8 Conical Stop

RS Stock number 811-2350

### RS Conical Buffers

The elastic buffers can be used in these two possibilities:

As Buffers:

The impact takes place as an end of stroke, taking into account the maximum deflection the stop may give.

As elastic mounts.


When installed as elastic mounts, the buffers may be screwed to the base of the machine so that its flat surface rests directly on the floor or ground.

#### Applications

As buffers: In any case for limiting a flexible element.

- End of stroke of spring or damper.
- End of stroke of cranes and hoists.
- Setting of fragile material in packing.

#### Technical data

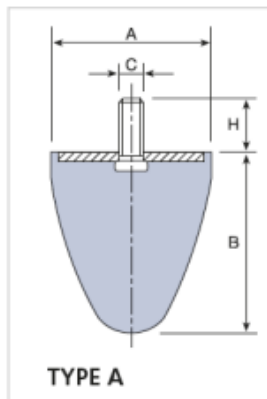

RS Ref:	AMC Ref:	A	B	C	H	COMPRESSION		
						LOAD max. daN	DEFLECT. mm	ENERGY a 1 m/s Kg. m.
8112319	115001	25	19	M-8	20	100	8	0,3
8112356	115002	30	30	M-6	16	140	15	0,6
8112350	115003	50	50	M-8	20	340	25	3
8112520	115004	50	64	M-8	35	370	32	4
8112558	115006	72	58	M-12	30	550	26	5