


# B 221309 PC-V0-G 7024



Bocube  
Enclosures, polycarbonate UL 94 V0, crystal-clear lid  
**Order no.: 96025234**

<b>Colour</b>	Graphite grey
<b>Colour of enclosure group</b>	Graphite grey, similar to RAL 7024; light grey, similar to RAL 7035; special colours on request
<b>Protection class</b>	IP 66/IP 67 DIN EN 60529
<b>Enclosure material</b>	ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C), foamed seal; for details please see Technical Information Scope of delivery: Lid and base, hinged quick-release catches

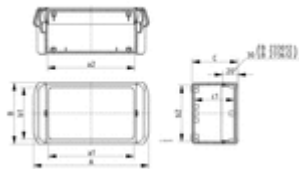

<b>A</b>	231 mm
<b>B</b>	125 mm
<b>C</b>	90 mm
<b>a1</b>	192 mm
<b>a2</b>	194,1 mm
<b>b1</b>	113 mm
<b>b2</b>	117,9 mm
<b>c1</b>	82 mm

<b>Technical drawings</b>	Catalogue drawing in DXF format: <a href="#">96025234_B-221309-PC-V0-G-7024.dxf</a> (3.9 MB) Catalogue drawing in PDF format: <a href="#">96025234_B-221309-PC-V0-G-7024.pdf</a> (260 KB) 3D product data in STEP format: <a href="#">Registration necessary</a> Basic drawing for processing work: <a href="#">96025234_B-221309-PC-V0-G-7024-G.dxf</a> (3.1 MB)
<b>Chapter download</b>	<a href="#">Bocube_GB.pdf</a> (459 KB) <a href="#">Highlights_Bocube.pdf</a> (3.8 MB)

## Accessories



### Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS

- 96310203 [B SC 13 PC-V0 1023](#) For B 1413.., B 1813.., B 2213.. Traffic yellow
- 96310205 [B SC 13 PC-V0 7035](#) For B 1413.., B 1813.., B 2213.. Light grey
- 96310204 [B SC 13 PC-V0 7024](#) For B 1413.., B 1813.., B 2213.. Graphite grey
- 96310209 [B SC 13 PC-V0 6029](#) For B 1413.., B 1813.., B 2213.. Mint green
- 96310202 [B SC 13 PC-V0 5002](#) For B 1413.., B 1813.., B 2213.. Ultramarine blue
- 96310200 [B SC 13 PC-V0 3000](#) For B 1413.., B 1813.., B 2213.. Flame red



### Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

- 96910203 [B SC HB 13 PC-V0 1023](#) For B 1413.., B 1813.., B 2213.. Traffic yellow
- 96910205\*\* [B SC HB 13 PC-V0 7035](#) For B 1413.., B 1813.., B 2213.. Light grey
- 96930205\*\* [B SC HB 13 ABS 7035](#) For B 1413.., B 1813.., B 2213.. Light grey
- 96910204\*\* [B SC HB 13 PC-V0 7024](#) For B 1413.., B 1813.., B 2213.. Graphite grey
- 96910209 [B SC HB 13 PC-V0 6029](#) For B 1413.., B 1813.., B 2213.. Mint green
- 96910202 [B SC HB 13 PC-V0 5002](#) For B 1413.., B 1813.., B 2213.. Ultramarine blue
- 96910200 [B SC HB 13 PC-V0 3000](#) For B 1413.., B 1813.., B 2213.. Flame red



### Wall brackets

- 96510004 [B WL 7024](#) For B 08... - B 26... Graphite grey
- 96510005 [B WL 7035](#) For B 08... - B 26... Light grey




### Mounting panels, laminated paper, 2 mm

- 96605200 [B M 2213](#) For B 2213..



### Front panels, 2 mm, natural-coloured anodised aluminium

- 96705200 [B FP 2213](#) For B 2213.., front panel thickness 2.0 mm

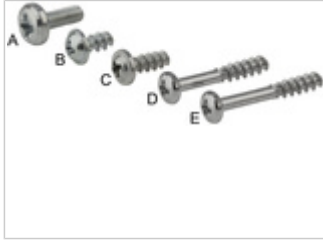


#### Sets of screws

96700000	<a href="#">B FP-SHR</a>	A (for fixing front panels)
96600010	<a href="#">B M-SHR</a>	C (for fixing mounting panels B M 1008-2736)
96300000	<a href="#">B SHR</a>	D (for optional screwing of enclosures B 0808 - 2617)




#### Distance bolts

96758000	<a href="#">DIBLZ AK</a> <a href="#">30x5/IM3/58</a>	ND = 2.4 - 2.6, for B...09
96756000	<a href="#">DIBLZ AK</a> <a href="#">30x7/IM3/56</a>	ND = 2.4-2.6, for B...09 if a mounting plate is used

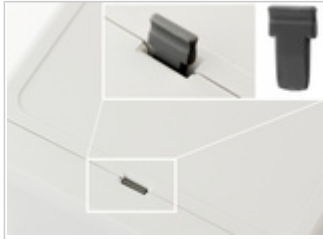

#### Blanking plugs to determine the hinge side

96410004	<a href="#">B VS 7024</a>	Graphite grey
96410005	<a href="#">B VS 7035</a>	Light grey
96410000	<a href="#">B VS 3000</a>	Flame red

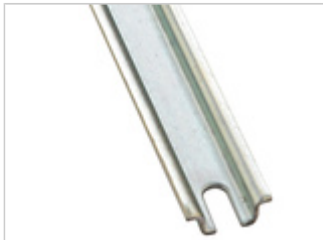

#### DIN rails DIN EN 60715 TH 15

22151901	<a href="#">TS 15</a>	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..
----------	-----------------------	---



#### DIN rails DIN EN 60715 G 32

22321901	<a href="#">TS 32</a>	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, B 22130.
----------	-----------------------	--



#### DIN rails DIN EN 60715 TH 35

22351901	<a href="#">TS 35</a>	For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..
----------	-----------------------	---

\* = Available on request