

Electromagnetic ballasts



Type: LN16.417 240V/50HZ

Item number: 164358

Standard version

Vacuum-impregnated with polyester resin


Lamp type:	TC-DD
Output [W]:	0016
Voltage [V]:	240
Shape [mm*mm]:	28x41
Stack length [mm]:	034
Fixing centre [mm]:	075
Overall length [mm]:	085
Protection from overheating:	Without thermal cut-out
Encapsulated:	No
Delta t Max. [K]:	60
Connection:	Push-in/IDC terminal
Earth terminal:	No
Frequency [Hz]:	50
Protection class:	Class of protection I

Unit: 10 pcs.

tw 130

EN 61347 (Safety)

EN 60921 (Working method)

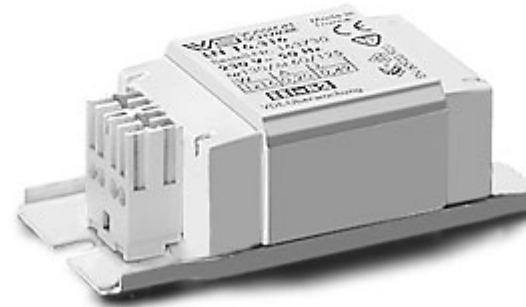

Electromagnetic ballasts

Type: LN16.417 240V/50HZ

Item number: B164358

