


200A – 2000A Non-fusible disconnect switches



For a complete assembly,
please select one of each:

- 1 switch
- 1 handle
- 1 shaft
- 1 terminal lug kit

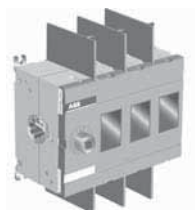

OT200U03




OX6X210




OHB80J6



OZXA-200

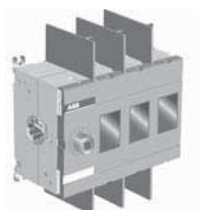

OT200U03

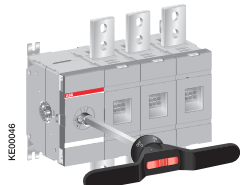

OT800U03P-OT1200U03P

200 Amp switches, 600V

CSA general purpose amp rating	CSA standard C22.2 No.	Maximum horsepower rating					Catalog number	List price
		Three phase						
		200V	208V	240V	480V	600V		
2 pole								
200	4	30/1Ph	40/1Ph	40/1Ph	—	—	OT200U02	
3 pole								
200	4	60	60	75	150	200	OT200U03	
200	4	60	60	75	150	200	OT200U12	
200	4	60	60	75	150	200	OT200U30	
4 pole								
200	4	60	60	75	150	200	OT200U04	

400 – 800 Amp switches, 600V

CSA general purpose amp rating	CSA standard C22.2 No.	Maximum horsepower rating					Catalog number	List price
		200V	208V	240V	480V	600V		
2 pole								
400	4	—	—	—	—	—	OT400U02	
600	4	—	—	—	—	—	OT600U02	
800	4	—	—	—	—	—	OT800U02	
3 pole								
400	4	100	100	125	250	350	OT400U03	
400	4	100	100	125	250	350	OT400U12	
400	4	100	100	125	250	350	OT400U30	
600	4	150	150	200	400	500	OT600U03	
600	4	150	150	200	400	500	OT600U12	
600	4	150	150	200	400	500	OT600U30	
800	4	200	200	250	500	500	OT800U03	
800	4	200	200	250	500	500	OT800U12	
800	4	200	200	250	500	500	OT800U30	
4 pole								
400	4	100	100	125	250	350	OT400U04	
600	4	150	150	200	400	500	OT600U04	
800	4	200	200	250	500	500	OT800U04	


1200 – 2000 Amp switches, 600V

① Maximum operating voltage: 480V

CSA general purpose amp rating	CSA standard C22.2 No.	Maximum horsepower rating	Catalog number	List price
2 pole				
1200	4	The Canadian Electric Code does not specify HP ratings for switches this large. Please select a switch based on 115% of application FLA. For example: a motor with an FLA of 800A would require a 1200A switch: 800A x 115% = 920A, the closest higher rated switch is 1200A.	OT1200U02	
1600	4		OETL-NF1600-2	
2000	4		OETL-NF2000-2 ^①	
3 pole				
1200	4		OT1200U03	
1200	4		OT1200U12	
1600	4		OETL-NF1600	
2000	4		OETL-NF2000 ^①	
4 pole				
—	—		OT1200U04	
—	—		OETL-NF1600-4	
—	—		OETL-NF2000-4 ^①	

200 – 1200 Amp change-over switches – bridging bars on page 1.14 to be ordered separately

CSA general purpose amp rating	CSA standard C22.2 No.	Maximum horsepower rating					Catalog number	List price
		200V	208V	240V	480V	600V		
3 pole								
200	4	60	60	75	150	200	OT200U03C	
400	4	100	100	125	250	350	OT400U03C	
600	4	150	150	200	400	500	OT600U03C	
800	4	200	200	250	500	500	OT800U03C	
4 pole								
200	4	60	60	75	150	200	OT200U04C	
400	4	100	100	125	250	360	OT400U04C	
600	4	150	150	200	400	500	OT600U04C	
800	4	200	200	250	500	500	OT800U04C	

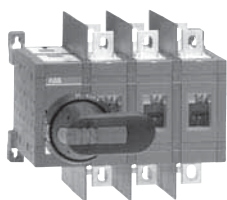

OT200U03CP