

---


## LIGHTIFY GARDENSPOT MINI RGB

LIGHTIFY Gardenspot Mini RGB | Mini LED spot lights/garden flood lights with LIGHTIFY technology, light color adjustable

---

### Areas of application

- Gardens
- Outdoor

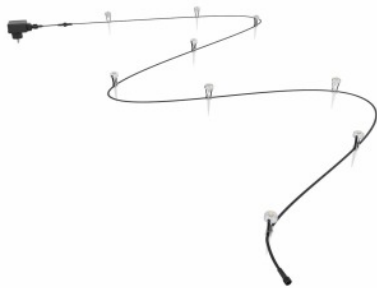

---

### Product benefits

- Controllable via smart devices (via Android and iOS)
- Complete LIGHTIFY function
- Easy to install and use
- Contains no mercury

---

### Product features

- RGB mini spot and garden floodlight with integrated smart lighting function
- RGB color control
- Dimmable via LIGHTIFY
- Type of protection: IP66 (luminaire), IP44 (ECG)



# Product datasheet

## Technical data

### Electrical data

Operating mode	E.Trafo
Nominal wattage	4.5 W
Nominal voltage	220...240 V
Mains frequency	50/60 Hz

 
### Photometrical data

Light color as per EN 12464-1	RGB
-------------------------------	-----

### Light technical data

Beam angle	30 °
Light color management	RGB color control

### Dimensions & weight



Length	23.0 mm
Width	23.0 mm
Height	96.0 mm

### Colors & materials

Body material	Polycarbonate (PC)
---------------	--------------------

### Temperatures

Ambient temperature range	-20...+40 °C
---------------------------	--------------

### Additional product data

Number of lighting outlets	9
----------------------------	---

# Product datasheet

## Capabilities

<b>Dimmable</b>	Yes <sup>1)</sup>
<b>Type of connection</b>	cable with plug
<b>LIGHTIFY technology</b>	Yes

<sup>1)</sup> Via Lightify function

## Certificates & standards

<b>Protection class</b>	II
<b>Type of protection</b>	IP66

## Country specific categorizations

<b>Order reference</b>	LIGHTIFY GARDEN
------------------------	-----------------

## Equipment / Accessories

- LIGHTIFY APP required
- LIGHTIFY Gateway required
- LIGHTIFY Gardenspot Mini RGB Add-on available

## Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899926134	LIGHTIFY GARDENSPOT MINI RGB	Shipping carton box 4	327 mm x 202 mm x 138 mm	9.12 dm <sup>3</sup>	2509.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

## Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.