



Datasheet

Stock No: 267-4170

ENGLISH

# RS Pro FDFNYD2 Series Blue Insulated Crimp Receptacle, 6.35 x 0.8mm, 16 → 14 AWG, Copper Plated



## Product Details:

### RS Pro Shrouded Female Receptacle Crimp Terminals

A range of fully insulated or shrouded double crimp female receptacle terminals made from brass with a copper sleeved barrel and flared nylon insulation. These shrouded female receptacle crimp connectors are colour coded for use with different wire sizes and accept a variety of tab sizes. For suitable crimp tool please see stock number 267-3133.



- Red 0.5 - 1.5 mm<sup>2</sup>
- Blue 1 - 2.6 mm<sup>2</sup>
- Yellow 2.5 - 6.5 mm<sup>2</sup>

## Approvals

UL Listed

# Specifications:

Tab Size: 6.35 x 0.8mm  
 Colour: Blue  
 Insulation: Insulated  
 Wire Size: 16 → 14 AWG  
 Gender: Female  
 Connector Type: Quick Disconnect Terminal  
 Series: FDFNYD2  
 Contact Material: Brass  
 Contact Plating: Copper  
 Length: 21.5mm  
 Insulation Material: Nylon

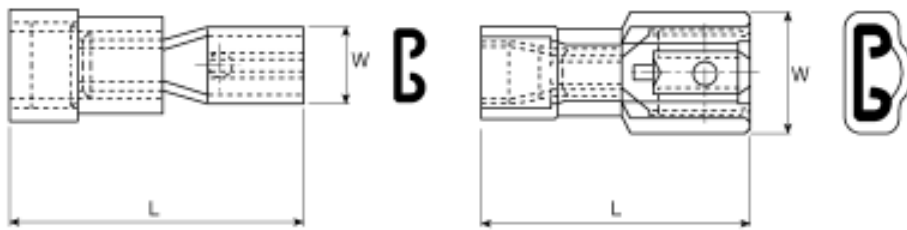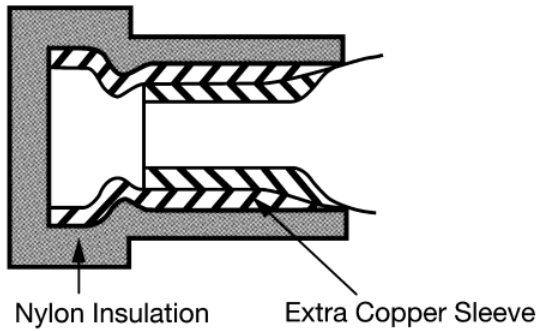

Type	Unshrouded						Shrouded					
	Red		Blue		Yellow		Red		Blue		Yellow	
	W	L	W	L	W	L	W	L	W	L	W	L
Size A	6.6	20.0	6.6	20.7	6.6	23.0	9.4	21.5	9.4	21.5	9.4	24.2
Size B	4.9	19.2	4.9	19.2			7.4	19.2	7.4	20.2		
Size C	5.0	19.2	5.0	19.2			7.4	19.2	7.4	20.2		
Size D	3.2	19.2					5.8	19.2				
Size E	3.2	19.2					5.8	19.2				