



Datasheet

Stock No: 748-2266

ENGLISH

RS Pro Orange Equipment Wire, 0.75 mm² CSA, 1000 V 18 AWG, 100m




BS 4808

Cable Construction

Conductor	Tinned Copper
square(mm ²)	0.75
Construction	T0.2±0.008×24
Standard Dia.(mm)	1.13
Insulation	PVC
Thickness	0.59
Insulation Dia.(±0.1mm)	2.30 +0.15/-0.1

Design

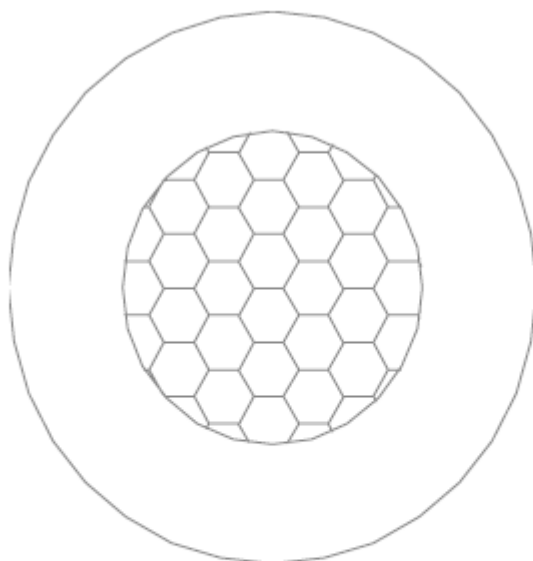

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<25.2
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	85
Rated Voltage (V)	1500

Manufactured to BS4800 (Technical Paints British Standards)

Flammability Test: IEC EN60332-1