

Product Datasheet


SCSI Ultra 320 HPDB68 M/F

Cable 2m, Screw type


RS Stock No. 8011180**ELECTRICAL SPECIFICATIONS**

1. Rating: Temp 80°C Voltage 30V
2. Conductor Resistance: AT 20°C MAX.
30AWG:376.96. Ω /KM
3. Impedance Resistance: 10M Ω /km min
at 20°C dc 500V
4. Dielectric Strength: AC 500V/1 minute.

SPECIFICATION

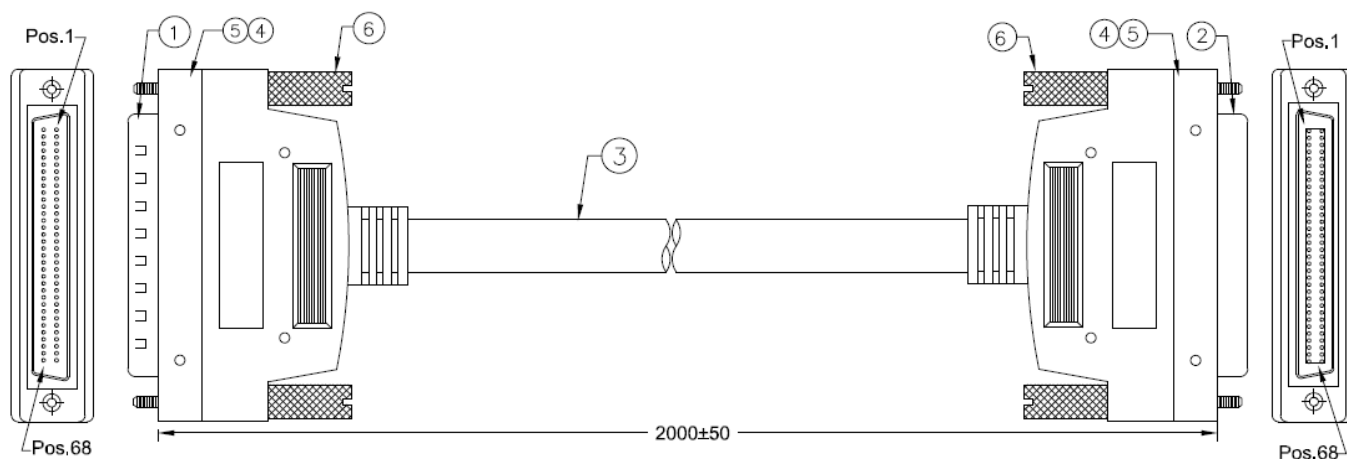

PIN ASSIGNMENT:

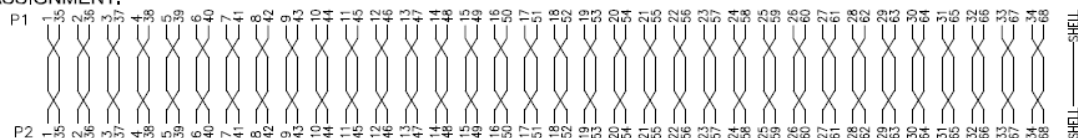

6	4	EA	MSM2P628440NIP0010	M2.6 All Metal Thumbscrew.
5	MM	SFC3010001		Copper Foil 360° Soldered
4	KG	DBPVCNU040BK01001		Molded 40P PVC Color:Black(BK01).
3	1	EA	W291930BK34PB0000M01	UL2919 30AWG 34TW/PR,Al/Mylar+Drain +Braid, Color:Black(BK01).
2	1	EA	CHPDB068FBK10U000104	HPDB68 Female, Pitch1.27mm, Shell: Tin Plated Contact:Gold 10U",Insulation:Black,PBT UL94V-0
1	1	EA	CHPDB068MBKTIN000024	HPDB68 Male, Pitch1.27mm, Shell: Tin Plated Contact:Gold 10U",Insulation:Black,PBT UL94V-0
ITEM	QTY	U/M	PART NO.	DESCRIPTION

Package:
1pcs/PE bag

