

Cable sleeve - CES-SRG-BK-2ASI-LR - 0801669

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Small, slotted cable sleeves suitable for two AS-i cables (L-R), material: NBR, version: left, right



Product description

Slotted sleeves for accommodating two pre-assembled AS-i cables (LL), can be used in CES sealing frames. When fitted, the sleeves also ensure strain relief according to DIN EN 50262.



Key commercial data

Packing unit	10 pc
GTIN	
Weight per Piece (excluding packing)	7.78 g
Custom tariff number	40169300
Country of origin	Taiwan

Technical data

Dimensions

Conductor sealing range	(AS-i cable)
-------------------------	--------------

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-40 °C ... 125 °C (static)

General

Product description	Slotted sleeves for accommodating two pre-assembled AS-i cables (LL), can be used in CES sealing frames. When fitted, the sleeves also ensure strain relief according to DIN EN 50262.
Material	NBR
Color	black

Cable sleeve - CES-SRG-BK-2ASI-LR - 0801669

Classifications

eCl@ss

eCl@ss 4.0	27081002
eCl@ss 4.1	27081002
eCl@ss 5.0	27081002
eCl@ss 5.1	27081002
eCl@ss 6.0	27081002
eCl@ss 7.0	27081002
eCl@ss 8.0	27081002

ETIM


ETIM 3.0	EC000879
ETIM 4.0	EC000451
ETIM 5.0	EC000451

UNSPSC

UNSPSC 6.01	30212109
UNSPSC 7.0901	39121708
UNSPSC 11	39121708
UNSPSC 12.01	39121708
UNSPSC 13.2	39121708

Drawings

Dimensioned drawing

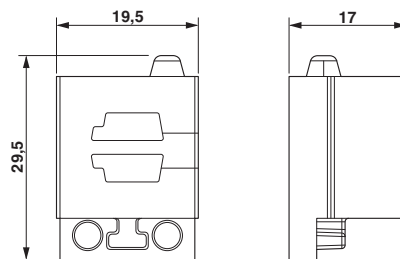

Dimensional drawing