

## Classic ECO Ball

CLAS.ECO BALL 28W E27 240V SLV

0023112

### Range features



### PRODUCT OVERVIEW

Ordering number	0023112
Light colour	828 Homelight
Technology	Halogen
Energy class	D
Average life (Rated) (h)	2000
Lamp finish	Clear
Lamp shape	Ball
Dimmable	Yes
Cap/Base	E27
Type	Ball ECO
EAN code	5410288231129
CRI (Ra)	100
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	345
Watt (Nominal) (W)	28
Equivalent watt (W)	35
Voltage (V)	240

# Classic ECO Ball

CLAS.ECO BALL 28W E27 240V SLV

0023112

## DATA TABLE

### General data

Ordering number	0023112
Technology	Halogen
Average life (Rated) (h)	2000
Average life (Nominal) (h)	2000
Energy class	D
Energy saving lamp	No
Lamp shape	Ball
Lamp finish	Clear
Dimmable	Yes
Cap/Base	E27
Type	Ball ECO
EAN code	5410288231129
E-number FI	4749587
E-number SE	8355971
Product name	CLAS.ECO BALL 28W E27 240V SLV
Lamp mercury content (mg)	0
Starting time (max) (s)	0.01
Warm-up time to 60% of full light (max) (s)	Instant full light
Control gear required	No
Fixture rating	Open
IEC Reference	IEC 60357
IEC Reference 2	IEC 60432-2
Intended purpose	General lighting
No. of switching cycles before premature failure (min)	> 8000
Special purpose lamp	No
Transformer required	No
Sales pack quantity	10
Optimal operating condition (°C)	25

### Optical data

Light colour	828 Homelight
CRI (Ra)	100
Suitable for accent lighting	No
Beam angle(°)	na
Colour temperature (K)	2800
Luminous flux (Rated) (lm)	345
Lumen maintenance at end of nominal life (%)	80
Luminous flux (Nominal) (lm)	345

# Classic ECO Ball

CLAS.ECO BALL 28W E27 240V SLV

**0023112**

## Electrical data

<b>kWh per 1000 hours burning time</b>	28
<b>Watt (Rated) (W)</b>	28
<b>Watt (Nominal) (W)</b>	28
<b>Equivalent watt (W)</b>	35
<b>Voltage (V)</b>	240
<b>Lamp power factor</b>	1

## Physical data


<b>Lamp Length (mm) - C/L</b>	74
<b>Lamp Diameter (mm) - D</b>	46
<b>Packaging outer width (cm)</b>	25
<b>Packaging outer length (cm)</b>	48.5
<b>Packaging outer height (cm)</b>	17.5
<b>Packaging single width (cm)</b>	4.55
<b>Packaging single length (cm)</b>	4.55
<b>Packaging single height (cm)</b>	7.6

## Classic ECO Ball

CLAS.ECO BALL 28W E27 240V SLV

0023112

### TECHNICAL DRAWINGS

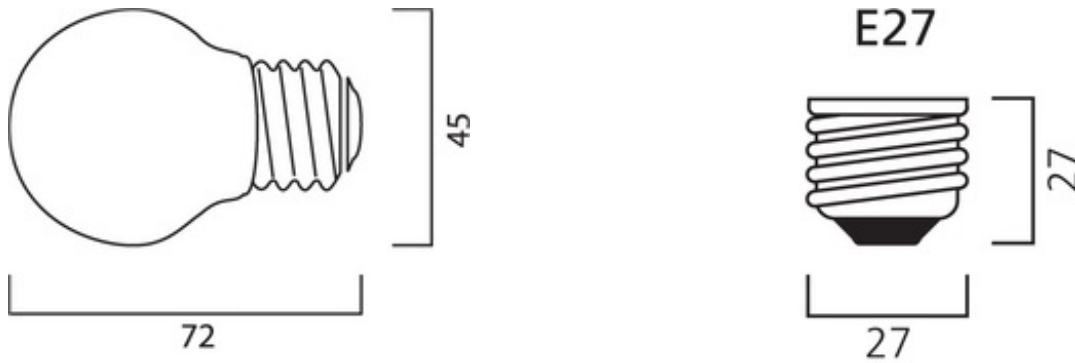

### ENERGY LABEL

