


# Height Adjusters

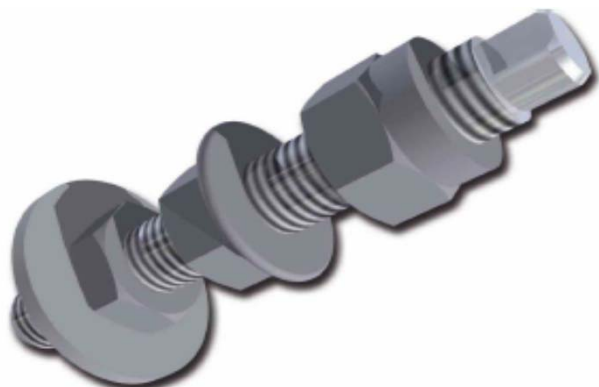

## Applications


- Gensets
- Marine Engines
- Diesel Engines
- Pumps
- HVAC
- Conveyors
- Machinery

Typical Assembly


Height Adjusters are available in various sizes to suit a wide range of mounts as listed in the table. They are designed to facilitate both levelling and securing of the respective equipment.

The Kits are supplied complete with Washer and Nut for Fastening to the Mounting, and also 2 x Nuts c/w Lock Washer for the Engine Foot Fastening.


KIT12-12-95

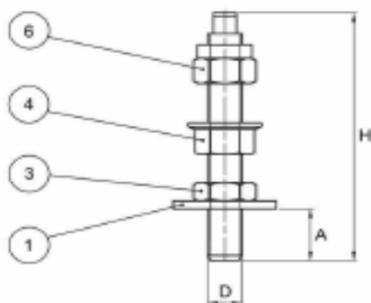

KIT12-16-105.5

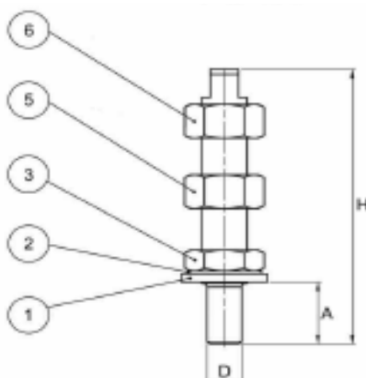



KIT16-16-110  
KIT20-20-135

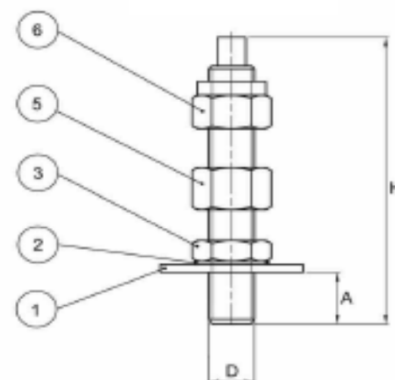

RS Ref:	Fibet Ref:	H	D	A	Washer	Locking Washer	Bottom Nut	Flange Nut	Adjusting Nut	Top Nut
					(Ref: 1)	(Ref: 2)	(Ref: 3)	(Ref: 4)	(Ref: 5)	(Ref: 6)
742-6831	KIT12-12-95	95	M12	20	36 x 14 x 3		M12	M12		M12
742-6834	KIT12-16-105.5	105.5	M12	24	28 x 15 x 2.5	■	M16		M16	M16
742-6838	KIT16-16-110	110	M16	20	48 x 17 x 3	■	M16		M16	M16
742-6847	KIT20-20-135	135	M20	30	60 x 22 x 3.5		M20		M20	M20



## Height Adjuster Applications

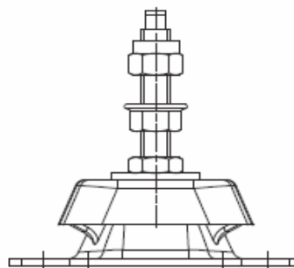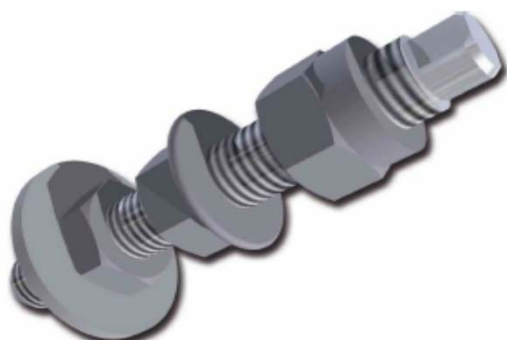

RS Mount Ref:	Fibet Mount Ref:	RS Ref: Fibet Ref:	Height Adjuster Option			
			742-6831	742-6834	742-6838	742-6847
			KIT12-12-95	KIT12-16-105.5	KIT16-16-110	KIT20-20-135
<b>Bobbin Mount End Stop - Type DE</b>						
720-3360	7540DE12-60		✓	✓		
<b>Rectangular Bell Mounts - Type CCFQ</b>						
720-3372	CCFQ804012-45		✓	✓		
720-3376	CCFQ804012-60		✓	✓		
720-3385	CCFQ804012-70		✓	✓		
720-3388	CCFQ1045016-45				✓	
720-3382	CCFQ1045016-60				✓	
720-3391	CCFQ1045016-70				✓	
720-3394	CCFQ1307020-45					✓
720-3398	CCFQ1307020-60					✓
720-3408	CCFQ1307020-70					✓
<b>Bell Mounts - Type CFAB</b>						
720-3473	CFAB-XW		✓	✓		
720-3477	CFAB-W		✓	✓		
720-3486	CFAB-K		✓	✓		
<b>Bell Mounts - Type CFBMH</b>						
720-3521	CFBMH923512M		✓	✓		
720-3512	CFBMH923512W		✓	✓		
720-3524	CFBMH1063816W				✓	
720-3528	CFBMH1063816M				✓	
720-3537	CFBMH1444816W				✓	
720-3530	CFBMH1444816M				✓	
<b>Bell Mounts - Type CFBMS</b>						
720-3495	CFBMS833512M		✓	✓		
720-3492	CFBMS833512W		✓	✓		
720-3499	CFBMS1064216W				✓	
720-3509	CFBMS1064216M				✓	
720-3502	CFBMS1505416W				✓	
720-3506	CFBMS1505416M				✓	