


C0805C155K8PACTU

aka C0805C155K8PAC7867

Capacitor, ceramic, 1.5 uF, +/-10% Tol, 10V, X5R, 0805

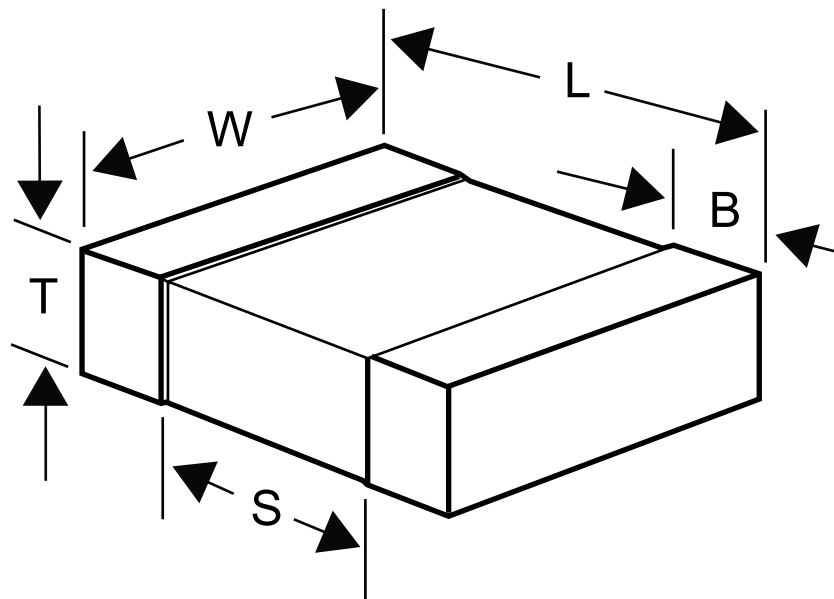

Dimensions (mm)

Specifications

| ID | Dimension | Tolerance | Manufacturer: | KEMET |
|----|-----------|-----------|--------------------------|-------------|
| L | 2.00 | +/-0.20 | Capacitance: | 1.5 uF |
| W | 1.25 | +/-0.20 | Chip Size: | 0805 |
| T | 0.78 | +/-0.1 | Voltage: | 10V |
| B | 0.50 | +/-0.25 | Temperature Coefficient: | X5R |
| S | 0.75 | min | Tolerance: | +/-10% |
| | | | Application: | Std Chip |
| | | | Termination Type: | Tin |
| | | | Marked: | No |
| | | | Dissipation Factor: | 10% |
| | | | Insulation Resistance: | 333.33 MOhm |
| | | | Dielectric Strength: | 25V |
| | | | Package Kind: | T&R |
| | | | Package Size: | 7in |
| | | | Package Type: | Paper Tape |
| | | | Package Quantity: | 4000 |