



ENGLISH


Datasheet

New 5.0mm Plug Straight 15A 4 way

RS Stock 874-4786



Dimensions: (mm)

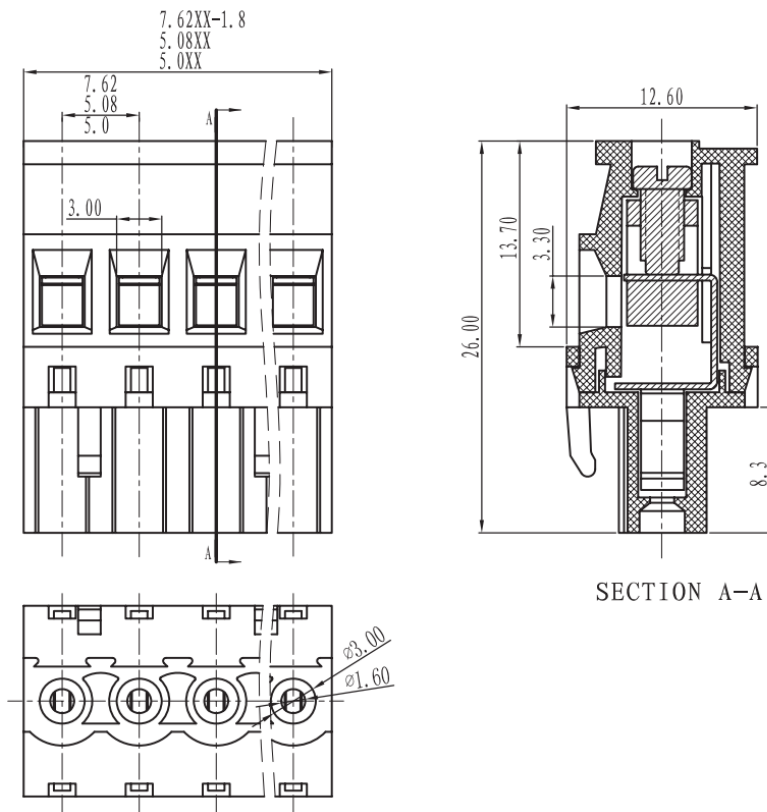



ENGLISH

Specifications

Electrical

Standard: UL IEC

Rated voltage: 300V 320V

Rated current: 15A 20A

Contact resistance: $20\text{m}\Omega$

Wire range: 28-14AWG 2.5mm^2

Withstanding voltage: AC2000V/1Min

Insulation resistance: $500\text{M}\Omega$ /DC500V

Mechanical

Temp.Range: -40°C ~ $+105^{\circ}\text{C}$

Torque: 0.5Nm(4.51lb`in)

Strip length: 7-8mm

Dimensions

Pitch: 5.0mm, 5.08mm, 7.62mm

Poles: 02P-24P

Material

Housing: PA66, UL94V-0

Screws: M3, steel Zinc plated

Clamp: Brass, Ni plated

wire guard: Phosphor bronze, Ni plated