


Data sheet

Commercial Art.No.: 56.703.2255.0

Earth terminal WKFN 2,5 2P/2F-SL

Ground terminal with tension spring connection for mounting on TS 35, nominal cross section: 2.5 mm², Width: 5 mm, Color: Green-yellow

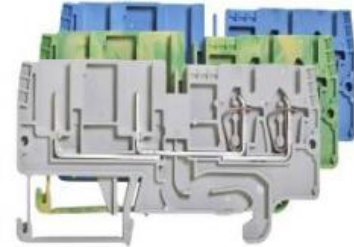

Commercial Art.No.	56.703.2255.0
EAN	4049088047893
Order Unit	100

Certificates / Approvals



Technical data

General

Nominal cross section	2.5 mm ²
Colour	Green/yellow
Number of levels	1
Number of clamp positions per level	4
Width/grid dimension	5 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	No

Technical data

Rated impulse voltage	8 kV
Pollution degree	3
Closing plate required	Yes
Type of insulation material	Thermoplastic
Length	85.05 mm

Connection Data

Connection type 1	Tension clamp connection
Connection type 2	Plug-in connection
Minimum cross section solid	0.2 mm ²
Maximum cross section solid	4 mm ²
Minimum cross section fine stranded	0.13 mm ²
Maximum cross section fine stranded	4 mm ²
Wire strip length	11 mm

Technical Data UL/CSA

Cross section UL	24-12 AWG
------------------	-----------

Voltage UL	500 V
Current factory wiring	20 A
Current field wiring	20 A
Cross section CSA	24-12 AWG
Voltage CSA	500 V
Current CSA	20 A

Classification

ECLASS 8.1	27141141
ETIM 7.0	EC000901
ETIM 6.0	EC000901
ETIM 5.0	EC000901
ETIM 4.0	EC000901
ETIM 3.0	EC000901

Accessories

Commercial Art.No.:	Article-type description:	Description:
---------------------	---------------------------	--------------

Fits with

Commercial Art.No.:	Article-type description:	Description:
---------------------	---------------------------	--------------