



Datasheet

DP Lever Microswitch, 0.5 A@ 125 V dc, 1.5 A@ 125 V dc, 10 A@ 125 V ac, 15 A@ 125 V ac

RS Stock 797-2551

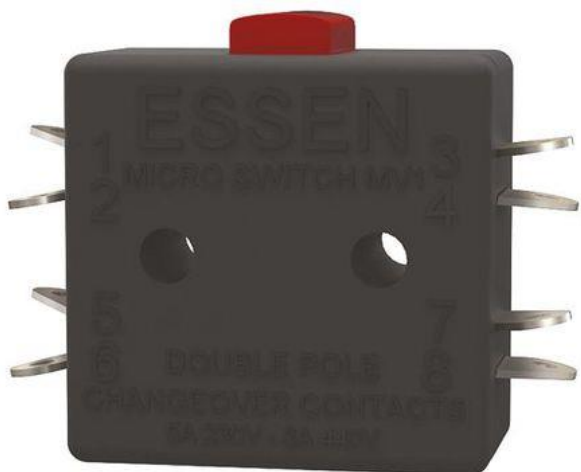

Dimensions: (mm)

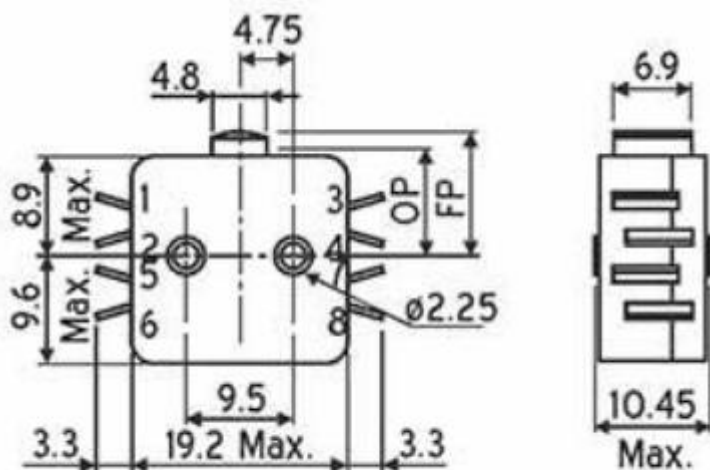

- 4 circuit, double pole, double – break
- Snap action through spring controlled pivoted contact carrying arms
- 2 NO + 2 NC contacts
- Long mechanical & electrical life
- Silver or Gold plated solder terminals
- Conform to IEC 1058-1



Specifications

Characteristics	
Actuating force	562 gms. (max)
Release force	60 gms. (min)
Movement differential	0.8mm (min)
Pre-travel	0.8 mm. (max)
Over-travel	Depress to case
Free Position	10.4mm (max)
Operating position	9.32 \pm 0.25mm (max)
Temperature Range	-65°C to +125°C
Salient features	Plain plunger actuator, Four Circuit, Eight solder tags