

PARATHOM SPECIAL T26 1.4 W/855 E14

PARATHOM SPECIAL T26 | Special LED lamps for refrigerators



Areas of application

- Small designer luminaires
- Accent lighting
- Outdoor use in outdoor luminaires only (minimum IP65)
- Sewing machines

Product benefits

- Very low energy consumption
- Long life
- Robust against vibrations
- Extremely small dimensions
- Lower thermal output (compared with the standard reference product)
- Three year guarantee

Product features

- Light Color: Cool White, Warm White
- Not suitable for use with dimmers
- Base: E14
- LED lamps for line voltage
- Mercury-free lamps
- Lifetime: up to 15,000 h



Technical data

Electrical data

Rated wattage	1.40 W
Nominal wattage	1.40 W
Nominal voltage	220 V
Operating frequency	50...60 Hz
Power factor λ	0.17
Energy consumption	2 kWh/1000h


Photometrical data

Nominal luminous flux	100 lm
Rated luminous flux	100 lm
Color temperature	5500 K
Color rendering index Ra	80
Lumen main.fact.at end of nom.life time	0.70
Light color as per EN 12464-1	Cool White
Lumen maintenance at end of service life	0.70

Light technical data

Warm-up time (60 %)	< 2.00 s
Starting time	0.0 s

Dimensions & weight

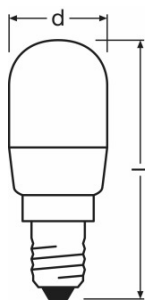

Product line drawing

Overall length	63.0 mm
Diameter	23.5 mm

Product datasheet

Outer bulb	T26
Length	63.0 mm


Colors & materials

Mercury-free	Yes
--------------	-----

Lifespan

Nominal lamp life time	25000 h
Rated lamp life time	25000 h
Number of switching cycles	200000

Additional product data

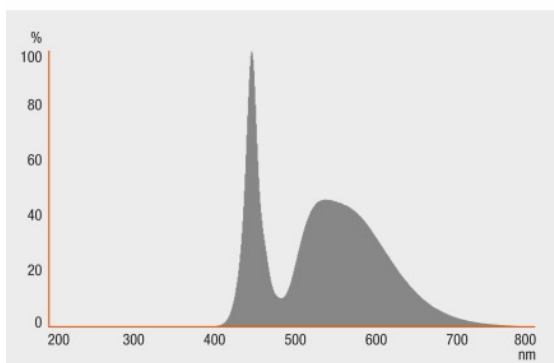

Spectral power distribution

Base (standard designation)	E14
New article	NEW
Design / version	Frosted
Appropriate disposal acc. to WEEE	Yes
Footnote only for product	All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value/In development, data preliminary/In

Product datasheet

	preparation
--	-------------

Capabilities

Dimmable	No
----------	----

Certificates & standards

Energy efficiency class	A++
-------------------------	-----

Country specific categorizations

ILCOS	DRNT/F-1,4-220-240-E14-23,5/63
Order reference	PT26 1,4W/855 2

Country specific information

Product code	METEL-Code	SEG number	STK-Number	UK Org
4052899907157	-	8334308	-	-

Product datasheet



Guarantee

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4052899907157	PARATHOM SPECIAL T26 1.4 W/855 E14	Folding carton box 1	66 mm x 26 mm x 26 mm	0.04 dm ³	14.00 g
4052899907164	PARATHOM SPECIAL T26 1.4 W/855 E14	Shipping carton box 20	76 mm x 107 mm x 132 mm	1.07 dm ³	308.00 g
4052899017795	PARATHOM SPECIAL T26 1.4 W/855 E14	Shipping carton box 120	248 mm x 145 mm x 229 mm	8.23 dm ³	1983.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

For Guarantee see

▶ www.osram.com/guarantee

For further products and actual information concerning LED lamps see

▶ www.osram.com/ledlamps

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.