

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

90156-0152

Status:


Active

Overview:

C-Grid III™

Description:

2.54mm Pitch C-Grid III™ Crimp Housing Single Row, 12 Circuits

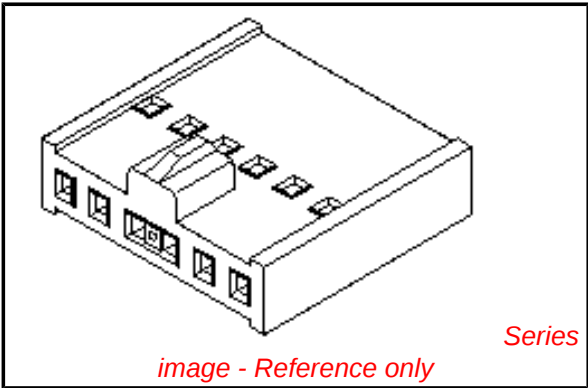

Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	90156
Application	Signal, Wire-to-Board
Overview	C-Grid III™
Product Name	C-Grid III™
UPC	800753667778
Physical	
Breakaway	No
Circuits (maximum)	12
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	0.920/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-55°C to +105°C

Electrical	
Current - Maximum per Contact	3A

Material Info

Reference - Drawing Numbers	
Sales Drawing	SDA-90156

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

90156Series

Mates With

90120 , 90121, 90136

Use With

90119

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION