


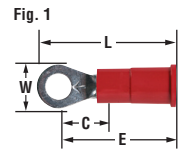


Highland™ Terminals and Splices. Provide a variety of design features assuring consistently effective, reliable performance and easy installation. Packaged in small quantities in reclosable plastic bags.

Vinyl Insulated Ring Tongue Terminals — Fig. 1

Stock No.	Mfr.'s Type	AWG	Stud Size	W	C	L	E	PER PKG./25
70233913	RV18-6Q	22-18	6	0.25	0.22	0.80	0.67	7.16
70233914	RV18-8Q	22-18	8	0.31	0.33	0.93	0.78	7.16
70233911	RV18-10Q	22-18	10	0.31	0.33	0.93	0.78	7.16
70233912	RV18-14Q	22-18	1/4"	0.47	0.40	1.08	0.85	7.16
70233909	RV14-6Q	16-14	6	0.25	0.22	0.80	0.67	7.16
70233910	RV14-8Q	16-14	8	0.25	0.22	0.80	0.67	7.16
70233906	RV14-10Q	16-14	10	0.33	0.29	0.90	0.74	7.16
70233907	RV14-14Q	16-14	1/4"	0.47	0.40	1.08	0.85	7.16
70233908	RV14-516Q	16-14	5/16"	0.47	0.40	1.08	0.85	7.16
70233905	RV10-8Q	12-10	8	0.38	0.29	1.03	0.84	8.95
70233901	RV10-10Q	12-10	10	0.38	0.29	1.03	0.84	8.95
70233902	RV10-14Q	12-10	1/4"	0.53	0.44	1.26	0.99	8.95
70233903	RV10-38Q	12-10	3/8"	0.54	0.44	1.26	0.99	8.95
70233904	RV10-516Q	12-10	15/16"	0.53	0.44	1.26	0.99	8.95



Vinyl Insulated Fork Terminals — Fig. 2

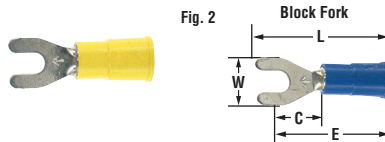


Stock No.	Mfr.'s Type	AWG	Stud Size	W	C	L	E	PER PKG./25
70233882	FV14-6Q	16-14	6	0.34	0.29	0.90	0.74	7.16
70233883	FV14-8Q	16-14	8	0.34	0.29	0.90	0.74	7.16
70233881	FV14-10Q	16-14	10	0.34	0.29	0.90	0.74	7.16
70233880	FV10-8Q	12-10	8	0.38	0.29	1.03	0.84	8.95
70233879	FV10-10Q	12-10	10	0.38	0.29	1.03	0.84	8.95

Vinyl Insulated Block Fork Terminals — Fig. 3




Stock No.	Mfr.'s Type	AWG	Stud Size	W	C	L	E	PER PKG./25
70233864	BFV18-6Q	22-18	6	0.25	0.25	0.85	0.70	7.16
70233865	BFV18-8Q	22-18	8	0.30	0.25	0.85	0.70	7.16
70233863	BFV18-10Q	22-18	10	0.30	0.25	0.85	0.70	7.16
70233861	BFV14-6Q	16-14	6	0.25	0.25	0.85	0.70	7.16
70233862	BFV14-8Q	16-14	8	0.30	0.25	0.85	0.70	7.16
70233860	BFV14-10Q	16-14	10	0.30	0.25	0.85	0.70	7.16
70233828	BFV10-6Q	12-10	6	0.32	0.29	1.03	0.84	8.95
70233829	BFV10-8Q	12-10	8	0.32	0.29	1.03	0.84	8.95
70233827	BFV10-10Q	12-10	10	0.32	0.29	1.03	0.84	8.95

Vinyl Insulated Locking Fork Terminals — Fig. 4

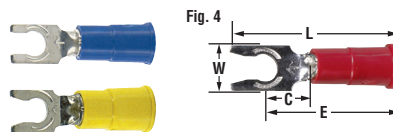


Stock No.	Mfr.'s Type	AWG	Stud Size	W	C	L	E	PER PKG./25
70233890	LFV18-6Q	22-18	6	0.25	0.25	0.88	0.70	7.16
70233891	LFV18-8Q	22-18	8	0.30	0.25	0.88	0.70	7.16
70233888	LFV14-6Q	16-14	6	0.25	0.25	0.88	0.70	7.16
70233889	LFV14-8Q	16-14	8	0.30	0.25	0.88	0.70	7.16
70233885	LFV10-6Q	12-10	6	0.28	0.28	1.03	0.83	8.95
70233886	LFV10-8Q	12-10	8	0.32	0.28	1.03	0.83	8.95
70233884	LFV10-10Q	12-10	10	0.32	0.28	1.03	0.83	8.95

 Vinyl Insulated Male Tabs — Fig. 5



Stock No.	Mfr.'s Type	AWG	Mates with Female Width × Thickness	L	PER PKG./25
70233899	MTV18-187Q	22-18	0.187 × 0.020	0.85	7.16
70233900	MTV18-250Q	22-18	0.250 × 0.032	0.93	7.16
70233897	MTV14-187Q	16-14	0.187 × 0.020	0.85	7.16
70233898	MTV14-250Q	16-14	0.250 × 0.032	0.93	7.16

 Vinyl Insulated Female Disconnects — Fig. 6



Stock No.	Mfr.'s Type	AWG	Mates with Male Tab Width × Thickness	L	PER PKG./25
70233877	FDV18-187Q	22-18	0.250 × 0.032	0.78	7.16
70233878	FDV18-250Q	22-18	0.250 × 0.032	0.87	7.16
70233875	FDV14-187Q	16-14	0.250 × 0.032	0.78	7.16
70233876	FDV14-250Q	16-14	0.250 × 0.032	0.87	7.16
70233874	FDV10-250Q	12-10	0.250 × 0.032	0.96	8.95

Fully Insulated Nylon Male Tabs — Fig. 7



Stock No.	Mfr.'s Type	AWG	Mates with Female Width × Thickness	L	W	D	PER PKG./25
70233895	MTI18-187Q	22-18	0.187 × 0.020	0.87	0.37	0.30	7.16
70233896	MTI18-250Q	22-18	0.250 × 0.032	0.98	0.44	0.30	7.16
70233893	MTI14-187Q	16-14	0.187 × 0.020	0.87	0.37	0.30	7.16
70233894	MTI14-250Q	16-14	0.250 × 0.032	0.98	0.44	0.30	7.16
70233892	MTI10-250Q	12-10	0.250 × 0.032	1.05	0.47	0.39	8.95

Fully Insulated Nylon Female Disconnects — Fig. 8



Stock No.	Mfr.'s Type	AWG	Mates with Male Tab Width × Thickness	L	W	D	PER PKG.
70233872	FDI18-187Q	22-18	0.187 × 0.020	0.81	0.30	0.23	7.16
70233873	FDI18-250Q	22-18	0.250 × 0.032	0.91	0.37	0.23	7.16
70233870	FDI14-187Q	16-14	0.187 × 0.020	0.81	0.30	0.23	7.16
70233871	FDI14-250Q	16-14	0.250 × 0.032	0.91	0.37	0.23	7.16
70233869	FDI10-250Q	12-10	0.250 × 0.032	0.99	0.39	0.32	8.95

Vinyl Insulated Butt Splices — Fig. 9



Stock No.	Mfr.'s Type	AWG	L	PER PKG./25
70233868	BSV18Q	22-18	1.00	11.63
70233867	BSV14Q	16-14	1.00	11.63
70233866	BSV10Q	12-10	1.02	6.27