



ENGLISH

## Datasheet

Stock No: 233-477

# RS Pro Black Nylon Non-Releasable Cable Tie, 292mm x 3.6 mm



## Product Specification


**Natural and Black Nylon:** standard cable ties made from U.L. approved nylon 6/6. Normal service temperature range: -40oC to 85oC. Flammability rating: UL 94V-2.

**Weather Resistant Nylon(ULTRA VIOLET):** Carbonate "A" was added for greater resistance to ultra violet light in outdoor application.

**Heat Stabilised Nylon:** Service temp. 135oC

**Standards:** Made to comply with mil-spec drawing no. MS-3367 tensile strength meets or exceed MIL-S-23190E standard.

## Dimensions

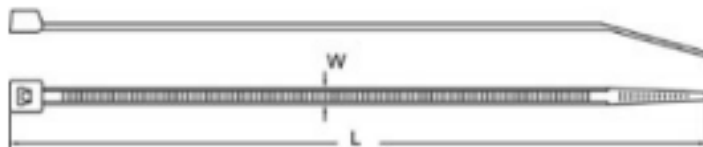

RS Article	Colour	Length (mm)	Width (mm)	Quantity	Min. Tensile Strength (Kg)	Max Bundle Dia. (mm)
178-462	Natural	100	2.5	100	8	22
233-499	Black	100	2.5	100	8	22
492-0447	Natural	100	2.5	1000	8	22
233-455	Black	100	2.5	1000	8	22

RS Article	Colour	Length (mm)	Width (mm)	Quantity	Min. Tensile Strength (Kg)	Max Bundle Dia. (mm)
178-478	Natural	150	3.6	100	18	36
233-465	Black	150	3.6	100	18	36
492-0453	Natural	150	3.6	1000	18	36
233-500	Black	150	3.6	1000	18	36
178-484	Natural	190	4.8	100	22	49
233-461	Black	190	4.8	100	22	49
492-0469	Natural	190	4.8	1000	22	49
233-506	Black	190	4.8	1000	22	49
489-2140	Natural	203	4.6	100	22	52
233-471	Black	203	4.6	100	22	52
178-490	Natural	292	3.6	100	18	82
233-477	Black	292	3.6	100	18	82
489-2156	Natural	300	4.8	100	22	83
233-487	Black	300	4.8	100	22	83
178-507	Natural	368	4.8	100	22	105
233-483	Black	368	4.8	100	22	105
233-493	Black	380	7.6	100	55	105