


Kits for Non-fusible disconnect switches 16A – 3150A, 600V, 3 pole^①

Each kit includes:

- 1 three pole^① switch
- 1 handle
- 1 shaft
- 1 terminal lug kit

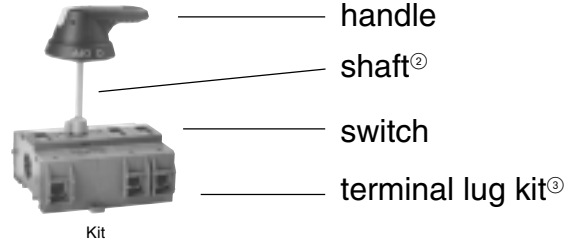

Kits with base & DIN rail mounted switches and selector handles

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price	
		Single phase		Three phase						
		120V	240V	200V – 208V	240V	480V	600V			
UL 508	16	16	1/2	1.5	3	5	10	10	OT16B2A1-180	\$ 100
	25	25	3/4	2	7.5	7.5	15	20	OT25B2A1-180	106
	40	40	1	3	10	10	20	25	OT32B2A1-180	110
UL 98	60	63	2	5	15	15	30	30	OT45B2A1-180	134
	80	80	2	5	20	20	40	40	OT63B2A1-180	154
UL 98	30	40	2	5	10	10	20	30	OT30B2A1-180	184
	60	63	3	7.5	20	20	40	40	OT60B2A1-180	209
	100	115	5	15	25	25	50	40	OT100B2A1-180	234

Kits with base and/or DIN rail mounted switches and pistol handles

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price	
		Single phase		Three phase						
		120V	240V	200V – 208V	240V	480V	600V			
UL 508	16	16	1/2	1.5	3	5	10	10	OT16B6-170	\$ 162
	25	25	3/4	2	7.5	7.5	15	20	OT25B6-170	168
	40	40	1	3	10	10	20	25	OT32B6-170	172
UL 98	60	63	2	5	15	15	30	30	OT45B6-170	196
	80	80	2	5	20	20	40	40	OT63B6-170	216
UL 98	30	40	2	5	10	10	20	30	OT30B6-170	246
	60	63	3	7.5	20	20	40	40	OT60B6-170	271
	100	115	5	15	25	25	50	40	OT100B6-170	296
UL 508	125	160	7.5	20	30	30	60	75	OT160B6-210	516
	175	200	—	—	30	40	75	100	OT175B8-240	724
	200	250	—	—	60	75	150	200	OT200B8-240	804
UL 98	400	630	—	—	100	125	250	350	OT400B4-280	1736
	600	800	—	—	150	200	400	500	OT600B4-280	2706
	800	1250	—	—	200	250	500	600	OT800B4-280	5066
UL 98	1200	1600	—	—	—	—	—	—	OT1200B4-280	7926
	1600	2500	—	—	—	—	—	—	OT1600M8-325	12,830
	2000	2500	—	—	—	—	—	—	OT2000M8-325	14,030
—	3150	—	—	—	—	—	—	OT3150M8-325	15,630	

Kits with door mounted switches

UL general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating						Kit catalog number	List price	
		Single phase		Three phase						
		120V	240V	200V – 208V	240V	480V	600V			
UL 508	16	16	1/2	1.5	3	5	10	10	OT16ET3S	\$ 98
	25	25	3/4	2	7.5	7.5	15	20	OT25ET3S	104
	40	40	1	3	10	10	20	25	OT32ET3S	108
UL 98	60	63	2	5	15	15	30	30	OT45ET3S	132
	80	80	2	5	20	20	40	40	OT63ET3S	152
UL 98	30	40	2	5	10	10	20	30	OT30ET3S	182
	60	63	3	7.5	20	20	40	40	OT60ET3S	207
	100	115	5	15	25	25	50	40	OT100ET3S	232
UL 98	30	40	2	5	10	10	20	30	OT30ET3P	254
	60	63	3	7.5	20	20	40	40	OT60ET3P	279
	100	115	5	15	25	25	50	40	OT100ET3P	304
125	160	7.5	20	30	30	60	75	OT160ET3P	640	

- ① Four poles are available — please reference accessories page.
- ② Shaft is not required with door mounted switch, except OT160ET3.
- ③ 16A – 125A switches include standard integral terminal lugs.
- ④ Available as a kit using the standard base mount switch and a door mount bracket.