

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [93287-0001](#)
Status: **Active**
Overview: SRC - Sealed Rectangular Connectors
Description: SRC Housing, Female, 84 Pin Signal, (84 x MX150™ Terminals) Nylon, Black

Documents:

Drawing (PDF)	Test Summary STR-1389 (PDF)
Product Specification PS-85070-001 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-85070-001 (PDF)	Product Literature (PDF)

General

Product Family	Crimp Housings
Series	93287
Application	Signal, Wire-to-Wire
Comments	Polarized to mating part
More Detailed Tech Information	Current (max.) for 84 way fully loaded 6A with 30° temp rise (AWG 14 MX150)
Overview	SRC - Sealed Rectangular Connectors
Product Literature Order No	987650-7391
Product Name	SRC
UPC	884982405226

Physical

Circuits (maximum)	84
Circuits Detail	84 x MX150™
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	121.830/g
Number of Rows	14
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	0.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +125°C

Electrical

Current - Maximum per Contact	18A
-------------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-85070-001
Product Specification	PS-85070-001
Sales Drawing	SD-93287-001
Test Summary	STR-1389

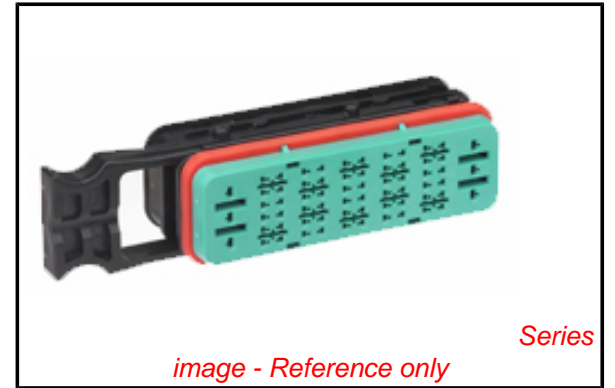


image - Reference only

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[93287Series](#)

Mates With

[93288 SRC Receptacle Housing](#)

Use With

[33012 MLX™ Receptacle Terminal](#)