
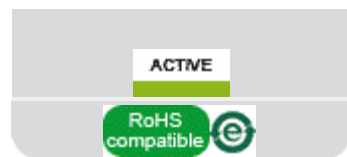


10073599-012LF - Minitek™
: Active Latch Housing,
Double Row, 12 Position

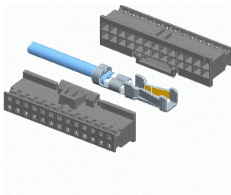

www.fci.com

Mating Half

10075025-G01-12ULF

Specifications

| General | |
|---------------------------------|--|
| Number of contacts (Total) | 12 |
| Number of rows | 2 |
| Product Type | Active Latch Housing |
| Mating half | Mates with 0.5 (0.02 in.) Square Pin. Mating Pin Length of 3.63 to 4 mm (0.143 to 0.157 in.) |
| Electrical | |
| Withstanding Voltage | 650V rms |
| Current rating | 2 amp Continuous |
| Resistance (Insulation) | 1000 M ohms min |
| Mechanical | |
| Durability (Mating cycles) | 50 |
| Physical | |
| Color (Housing) | Black |
| Material (Housing) | Thermoplastic |
| Temperature (Operating - range) | -55°C to +125°C |
| Approvals / Certifications | |
| UL File Number | E66906 |
| CSA File Number | LR46923 |
| Approvals / Certifications | UL and CSA Approved |
| Other Features | |
| Packaging (Type) | Bag |