
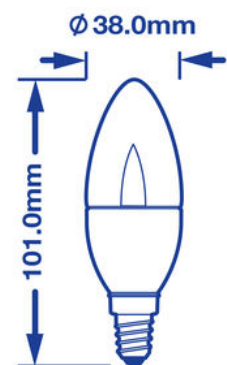


Verbatim LED VxRGB Natural Vision Candle E14 2.5W

1900K Warm White 50 LM


- E14 Socket
- 220 - 240 Voltage
- 25,000 hours Lifetime
- 64% Energy Saving
- Lumen: 50
- Special features: VxRGB Natural Vision - 1900K candle-like warm light

Product Number	52243
General Data	
Lamp Socket	E14
Electric Data	
Wattage (W)	2.5
Voltage (V)	220 - 240
Dimmable	no
Power Factor	0.40
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	101
Diameter (in mm)	38
Weight (g)	52
Photometric Data	
Luminous Flux (lm)	50
CRI	85
CCT (K)	1900
Beam Angle (°)	100
Luminous Efficacy (lm/W)	20
Lifetime (hrs)	25,000
Switching Cycle	20,000

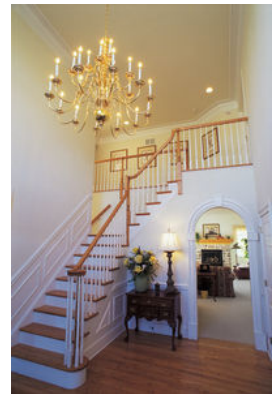

02/07/2014

Energy Rating

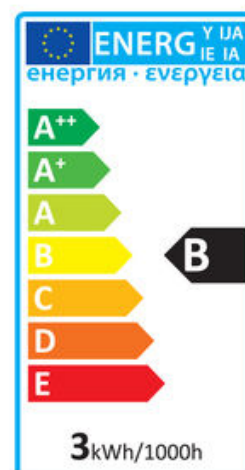

Technical Packaging Details

Barcode

023942522430

EAN 128

(02)00023942522430(37)04(91)204

EAN 14

50023942522435

Pack Dimensions(HxWxL)

117 x 40 x 40

Pack Weight

65

MOQ

10

Carton Dimensions (HxWxL)

146 x 95 x 223

Cartons/Pallet

198

Layers/Pallet

6

Units/Pallet

1980

02/07/2014