

Contact insert - SACC-CI-M 8FS-3CON-L90 - 1437067


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sensor/actuator flush-type connector, socket, 3-pos., M8, with angled solder connection, only contact insert



Key commercial data

Packing unit	50 pc
Minimum order quantity	50 pc
GTIN	 4 046356 448215
Weight per Piece (excluding packing)	2.33 g
Custom tariff number	85366990
Country of origin	Germany
Note	Made to Order (non-returnable)

Technical data

General

Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	3
Contact resistance	≤ 3 mΩ
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Status display	No
Surge voltage category	II
Pollution degree	3
Connection method	Solder pins

Material

Inflammability class according to UL 94	HB
Contact material	CuSn
Contact surface material	Au

Contact insert - SACC-CI-M 8FS-3CON-L90 - 1437067

Technical data

Material

Contact carrier material	PA 66
--------------------------	-------

Classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27143423
eCl@ss 5.1	27143423
eCl@ss 6.0	27279220
eCl@ss 7.0	27440103

ETIM


ETIM 3.0	EC002061
ETIM 4.0	EC002061
ETIM 5.0	EC002061

UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501
UNSPSC 12.01	31251501
UNSPSC 13.2	31251501


Drawings

Schematic diagram

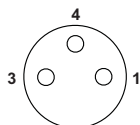

Pin assignment M8 socket, 3-pos., view female side


Drilling diagram

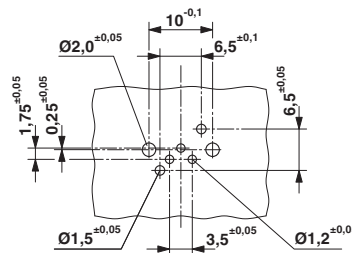

M8 flush-type socket

Contact insert - SACC-CI-M 8FS-3CON-L90 - 1437067

Dimensioned drawing

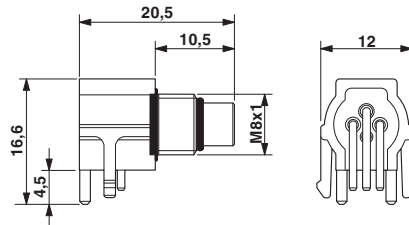

Contact carrier M8