 


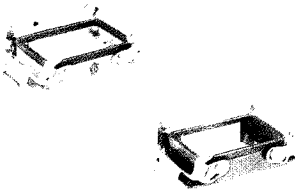
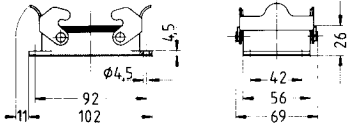
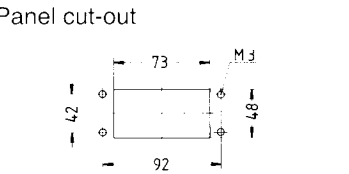
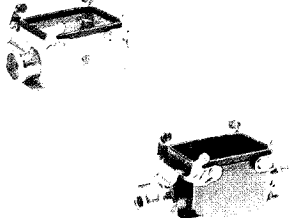
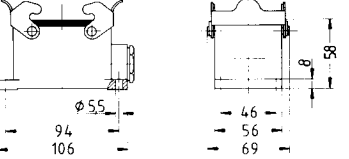

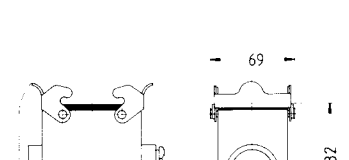
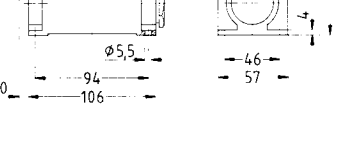
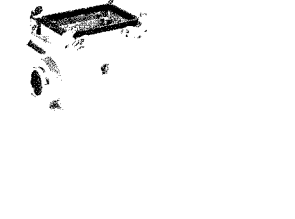
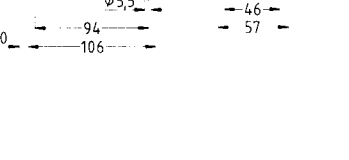

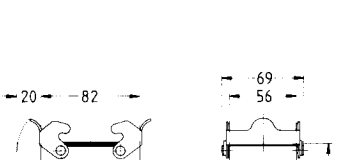
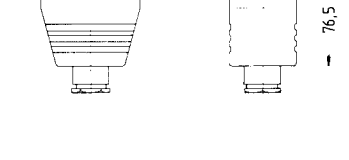


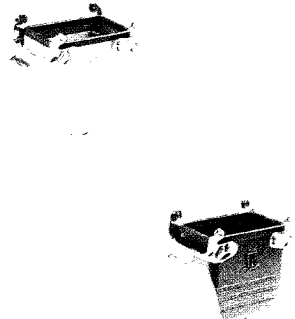
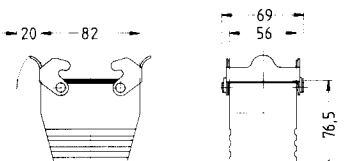
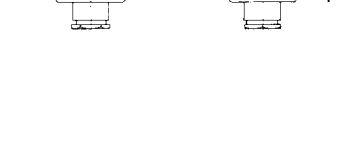



# Locking clip on hoods and housings

Style	Ordering number	Cable entry			Description	Outline drawing dimensions in mm
		 PG	 PG	 PG		
<b>Surface-mounted housing</b> bottom entry						
						
	41.50.32.00				HA.32.AG-VS	
	51.41.50.32.00				HA-K.32.AG-VS	
<b>Surface-mounted housing</b> side entry standard construction						
						
	41.60.32.07	21			HA.32.SG-VS.1.21	
	41.60.32.80		21		HA.32.SG-VS.1.21.Z	
	41.60.32.08	2x21			HA.32.SG-VS.2.21	
	41.60.32.96		2x21		HA.32.SG-VS.2.21.Z	
	51.41.60.32.07	21			HA-K.32.SG-VS.1.21	
	51.41.60.32.80		21		HA-K.32.SG-VS.1.21.Z	
	51.41.60.32.08	2x21			HA-K.32.SG-VS.2.21	
	51.41.60.32.96		2x21		HA-K.32.SG-VS.2.21.Z	
high construction						
						
	49.60.50.07	21			HD.50.SG-VS.1.21	
	49.60.50.80		21		HD.50.SG-VS.1.21.Z	
	49.60.50.08	2x21			HD.50.SG-VS.2.21	
	49.60.50.96		2x21		HD.50.SG-VS.2.21.Z	
	49.60.50.47	29			HD.50.SG-VS.1.29	
	49.60.50.81		29		HD.50.SG-VS.1.29.Z	
	49.60.50.48	2x29			HD.50.SG-VS.2.29	
	49.60.50.97		2x29		HD.50.SG-VS.2.29.Z	
	51.49.60.50.07	21			HD-K.50.SG-VS.1.21	
	51.49.60.50.80		21		HD-K.50.SG-VS.1.21.Z	
	51.49.60.50.08	2x21			HD-K.50.SG-VS.2.21	
	51.49.60.50.96		2x21		HD-K.50.SG-VS.2.21.Z	
	51.49.60.50.09	29			HD-K.50.SG-VS.1.29	
	51.49.60.50.81		29		HD-K.50.SG-VS.1.29.Z	
	51.49.60.50.48	2x29			HD-K.50.SG-VS.2.29	
	51.49.60.50.97		2x29		HD-K.50.SG-VS.2.29.Z	
<b>Cable-to-cable hood</b> bottom entry high construction						
						
	49.70.50.07	21			HD.50.KDO-VS.1.21	
	49.70.50.80		21		HD.50.KDO-VS.1.21.Z	
	49.70.50.70			21	HD.50.KDO-VS.1.21.G	
	49.70.50.09	29			HD.50.KDO-VS.1.29	
	49.70.50.81		29		HD.50.KDO-VS.1.29.Z	
	49.70.50.71		29		HD.50.KDO-VS.1.29.G	
	51.49.70.50.07	21			HD-K.50.KDO-VS.1.21	
	51.49.70.50.80		21		HD-K.50.KDO-VS.1.21.Z	
	51.49.70.50.70			21	HD-K.50.KDO-VS.1.21.G	
	51.49.70.50.09	29			HD-K.50.KDO-VS.1.29	
	51.49.70.50.81		29		HD-K.50.KDO-VS.1.29.Z	
	51.49.70.50.71		29		HD-K.50.KDO-VS.1.29.G	