

## Numeric Serial Data Displays

- Compact 96 x 24mm panel mounting numeric unit
- Display RS485, RS232 or TTY (passive) serial data inputs
- 6 digit, 13 mm red LED display
- Rugged metal case
- IP65 front panel with supplied gasket
- 24 VDC supply
- Self test function




### Specifications


Display	Six 7-segment, 13 mm red LEDs
Interface	RS485, RS232 or TTY (passive)
Display characters	0 to 9 and A, b, C, d, E, F, n, o, P, r, U, -, .
Protocol	ASCII
Baud rate	1200 to 9600 Baud; Even, Odd or No parity
Addresses	01 to 99
Front protection	IP65 with supplied gasket
Dimensions	96 x 24 mm, depth 60 mm
Panel cut-out	93 x 22.2 mm
Operating temperature	0 to +50 °C
Storage temperature	-25 to +70 °C
Power supply	24 VDC $\pm$ 20 %, 120 mA

### Application Example:

As serial slave display in PLC, PC or mainframe computer industrial control applications

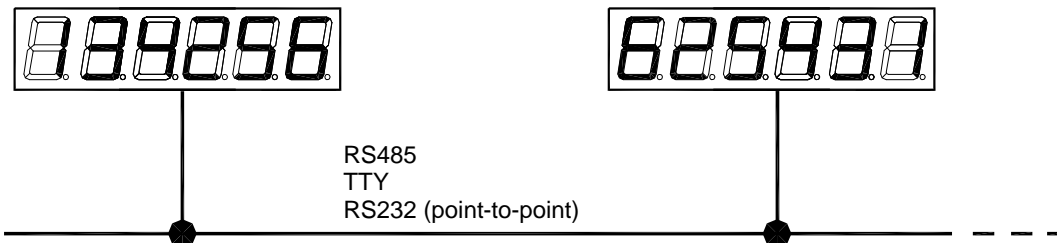

### Dimensions:

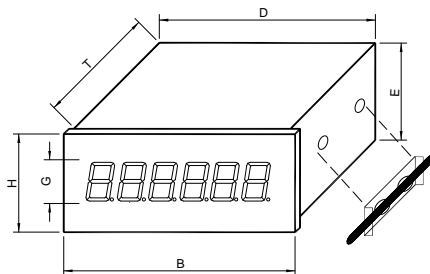

#### Also available:

- Numeric Profibus-DP data displays
- Alpha-Numeric Profibus and Serial data displays

Digits	Character height G	B	H	D	E	T
	mm	mm	mm	mm	mm	mm
6	13	96	24	91.5	20	60

### Stocked by RS Components Ltd

Description	Model	Part Number	RS Stock No.
6-digit serial data display	MI-PAN-SI6R13	KSI6LE1-I8121462	711-6023

Mipan-SI\_GB1007