


Ignitors

Ignitor Electrical Data

Supply Voltage	220/240V ±10% 50/60Hz
Wattage (W)	35-70
Timed	Y
Ignitor Type	Superimposed
Max Lamp Current (A)	2
Pulse Magnitude (kV)	1.8-2.3
Max. Lead Capacitance (pf)	200
Max Case Temp (°C)	105
Internal Temp (°C)	20

Physical Data

Dimensions (Dia. x L mm)	40x75
Fixings (mm)	M8x10
Weight (kg)	0.18

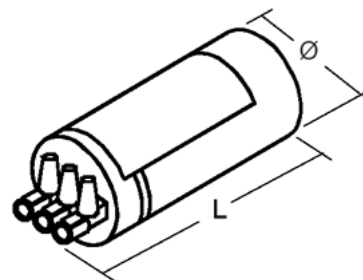

Revision: 17-07-2013

See page 2 for product notes



Product Code: PCX070255

Ignitors

Notes: