


# 3 U, 5 slot

Part no.: 20836-310



## Features:

- System for horizontal board mounting at front with board format
  - Front: 6 U, 160 mm deep
- VME backplane
  - 5 slots, 6 U, J1/J2 monolithic
- Open frame power supply, 250 W
- Heat dissipation with one fan; temperature-controlled by fan control module (FCM)
- Display module for DC operating voltage, fan and temperature alarm

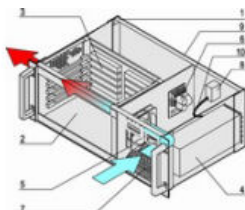

VITA

RoHS  
COMPLIANT

## Technical information:

Height	Height	Depth	No. of slots	Description
3 U	132.55 mm	277.5 mm	5	3 U, 5 slot

**Delivery comprises:** completely assembled, wired and tested

Item	Qty	Description
1	1	Shielded 19" chassis, Al, with perforated side panels; front handles (RAL 7016)
2	5	Front slot; IEEE guide rails, incl. ESD clips (ESD clips fitted to the right), for horizontal board mounting (6 U, 160 mm deep)
3	1	VME backplane for 6 U boards, 5 slots, J1/J2 monolithic; technical data under <a href="http://www.schroff.biz/oneclick">www.schroff.biz/oneclick</a> enter 23001-065
4	1	Power supply unit, open frame; 250 W; technical data under <a href="http://www.schroff.biz/oneclick">www.schroff.biz/oneclick</a> enter 11098-316
5	1	Fan; temperature-dependent speed control
6	1	Fan control module (FCM) for fan monitoring and control; technical data under <a href="http://www.schroff.biz/oneclick">www.schroff.biz/oneclick</a> enter 23207-021
7	1	Front panel, perforated, 3 U; display module; mains switch
8	1	AC mains input (IEC 320-C14 plug), mains filter, mains fuse
9	1	Rear panel, Al
10	1	Cable harness to connect all system components

## Note:

- System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to VITA 1.1-194
- Please order equipment cable separately  
Please order 19" case separately